



MQDEC1-803SS

▶ DOUBLE-ENDED CORDSETS



Cordset: Double-Ended M12 to M12

8-pin Straight Female


8-pin Straight Male

1 m 8x24 PVC Black

Nickel-Plated Brass Coupling Nut(s)

Part Number: 813646

CERTIFICATIONS

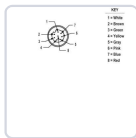

SPECIFICATIONS

IP Rating	IP67
Connector 1 Type	M12
Connector 2 Type	M12
Connector 2 Number of Contacts	8
Cable Jacket Material	PVC
Coupling Nut Material	Nickel Plated Brass
Connector 1 Number of Contacts	8
Number of Ends	Double Ended

Chat with an Expert

Cordset Length Range (m)	Less than 2.00
Connector 1 Key Code	A
Minimum Temp. (Celsius)	-40
Maximum Temp. (Celsius)	70
Shield/No Shield	No Shield
Overmold Material and Color	PUR Black
Current Rating (A)	2.0
Voltage Rating (V)	30 V ac/dc
Connector 2 Key Code	A
Connector 2 Orientation	Straight
Connector 1 Orientation	Straight
Cordset Length (m)	1
Connector 2 Gender	Male
Outside Cable Diameter (mm)	5.9
Connector 1 Gender	Female

Cookies

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List. To learn more, visit our [privacy policy](#).



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America

Chat with an Expert

Cookies

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.

To learn more, visit our [privacy policy](#).