

# ABP1412

---



Sample image

**Order symbol:** ABP1412

**Product nbr:** 8592171

**Description:** Painted Steel Back Panel


**Remarks:**

**EAN:** 6418074067876

**Including:**

**El. number:**

- Finland:
- Denmark:
- Sweden:

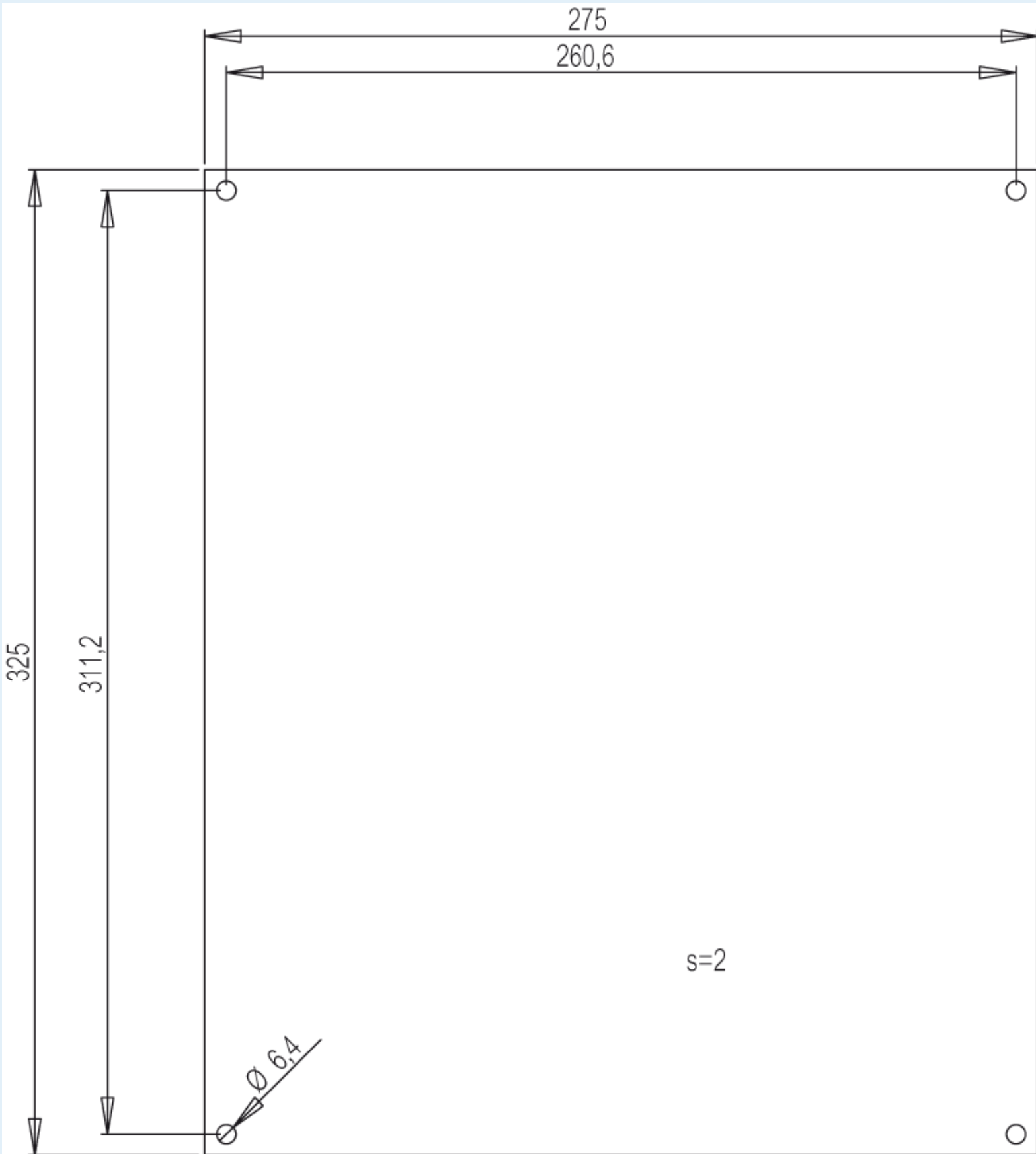

**Dimensions:**

	Height	Width	Depth
mm:	325	274	
inch:	12.8	10.8	

**Rating:**

Ingress protection (EN 60529):  
 Impact Resistance (EN 62262):  
 Electrical insulation:

Not insulated

**Materials:**

Material: Steel

Base colour:

Cover colour:

Gasket material:

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

**Temperatures:**

Temperature °C (short term)::

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

**Certificates:**