

AR16148SCT



Sample image

Order symbol: AR16148SCT

Product nbr: 8561073

Description: PC Enclosure


Remarks: Transparent screw cover

EAN: 6418074066442

EI. number:

- Finland:
- Denmark:
- Sweden:

Including: Screw cover. Base with 10-32 brass inserts, cover with formed in place PUR gasket and 4 stainless cover screws. Enclosure mounting foot kit. Accessory 10-32 screws for panel mounting.

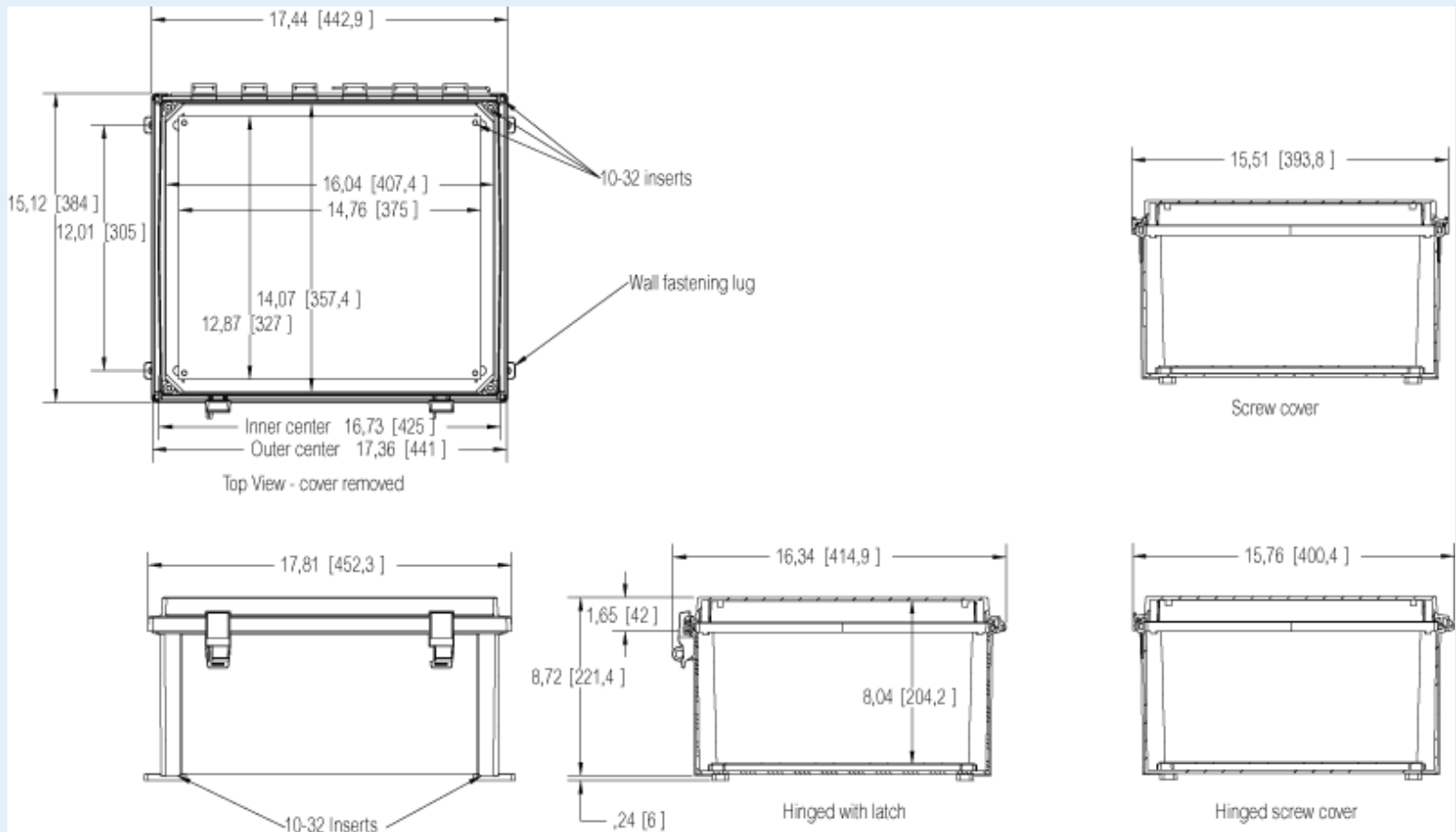

Dimensions:

mm:	Height	Width	Depth
	406	356	203

Accessories:

ALBP1614	Aluminum Back Panel
----------	---------------------

inch: 16 14 8

Materials:

Material: Polycarbonate
Base colour: RAL 7035 -light grey
Cover colour: Transparent
Gasket material: Polyurethane

Temperatures:

Temperature °C (short term):: -40 ... 140
Temperature °C (continuous): -40 ... 80
Temperature °F (short term): -40 ... 250
Temperature °F (continuous): -40 ... 175

(375 x 327)

ASPHK16 Swing Panel Kit w/o Panel
ADFP1614 Dead Front Panel w/ screws
(362 x 415 x 0)
APBP1614 PVC Back Panel
(375 x 327)
ABP1614 Painted Steel Back Panel
(375 x 327)
AMFL14 14" Mounting Flange Set
ASPK1614 Swing Panel Kit incl. Panel

Rating:

Ingress protection (EN 60529): IP66; IP67;
Impact Resistance (EN 62262): IK09;
Electrical insulation: Not insulated
Halogen free (DIN/VDE 0472, Part 815): 1
UV resistance: UL 508
Flammability Rating: UL 508
Glow Wire Test (IEC 695-2-1) °C: 960 °C
NEMA Class NEMA 4, 4X, 12 and 13

Certificates:

ARCA_CertificateofCompliance