

AR181610CHL



Sample image

Order symbol: AR181610CHL

EAN: 6418074067210

Product nbr: 8561069


El. number:

Description: PC Enclosure

- Finland:
- Denmark:
- Sweden:

Remarks: Hinged opaque cover w/Plastic quick release latch

Including: Hinged cover. Base with 10-32 brass inserts, latched cover with formed in place PUR gasket, stainless hinge pin. Quick release latches. Enclosure mounting foot kit. Accessory 10-32 screws for panel mounting.

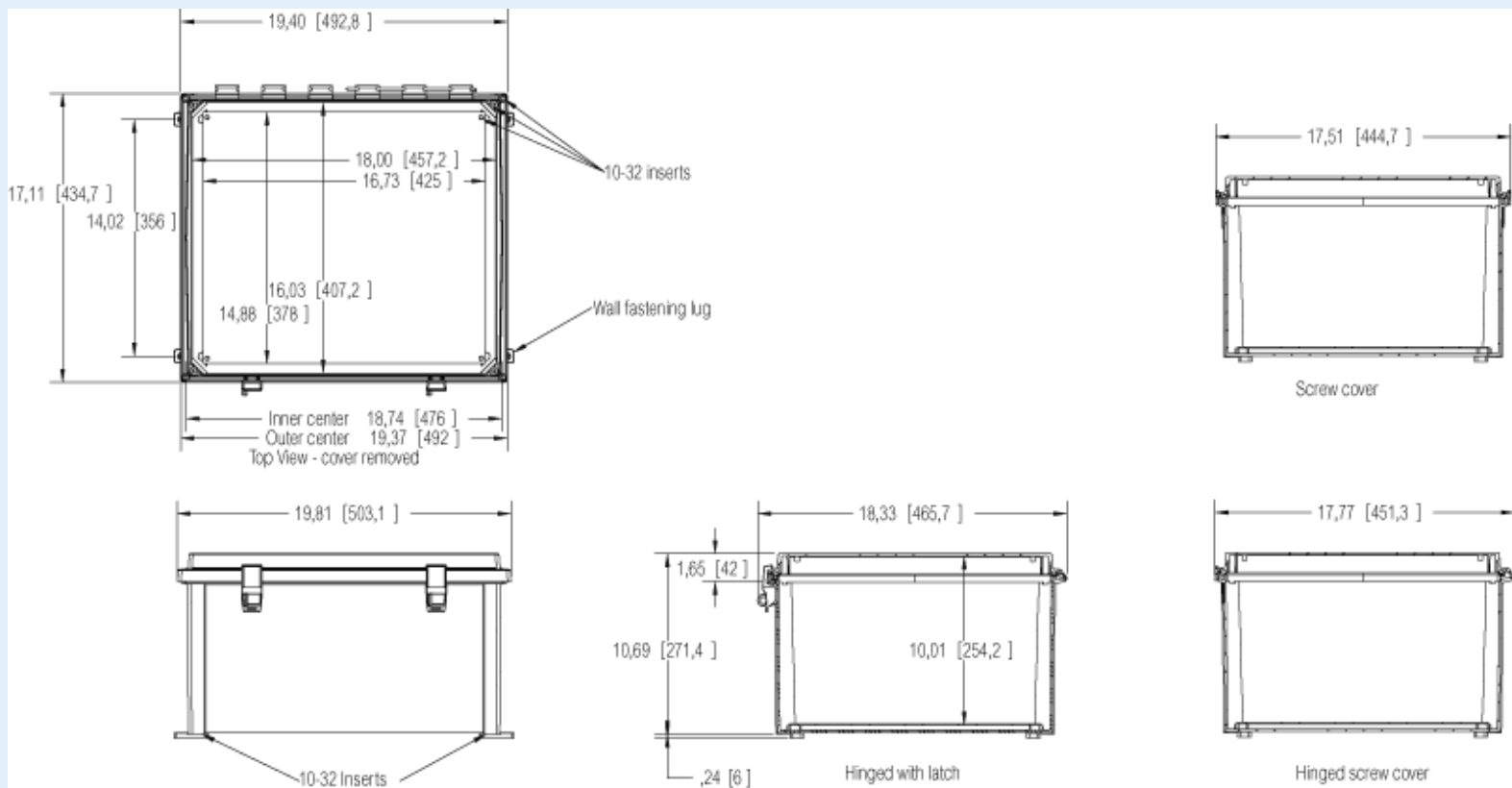

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm: | 457 | 406 | 254 |
| inch: | 18 | 16 | 10 |

| Accessories: | |
|--------------|--------------------------------------|
| APBP1816 | PVC Back Panel (424 x 378) |
| ABP1816 | Painted Steel Back Panel (424 x 378) |
| ASP1816 | Aluminum Swing Panel |

Materials:

| | |
|------------------|----------------------|
| Material: | Polycarbonate |
| Base colour: | RAL 7035 -light grey |
| Cover colour: | RAL 7035 -light grey |
| Gasket material: | Polyurethane |

Temperatures:

| | |
|-------------------------------|-------------|
| Temperature °C (short term):: | -40 ... 140 |
| Temperature °C (continuous): | -40 ... 80 |
| Temperature °F (short term): | -40 ... 250 |
| Temperature °F (continuous): | -40 ... 175 |

(410 x 465 x 0)

| | |
|----------|---|
| ALBP1816 | Aluminum Back Panel (424 x 378) |
| ADFP1816 | Dead Front Panel w/ screws (412 x 465 x 0) |
| AMFL16 | 16" Mounting Flange Set |
| ASPK1816 | Swing Panel Kit incl. Panel |

Rating:

| | |
|--|-----------------------|
| Ingress protection (EN 60529): | IP66; IP67; |
| Impact Resistance (EN 62262): | IK09; |
| Electrical insulation: | Not insulated |
| Halogen free (DIN/VDE 0472, Part 815): | 1 |
| UV resistance: | UL 508 |
| Flammability Rating: | UL 508 |
| Glow Wire Test (IEC 695-2-1) °C: | 960 °C |
| NEMA Class | NEMA 4, 4X, 12 and 13 |

Certificates:

ARCA_CertificateofCompliance