



### High Performance

4K, UHD, 3D, Audio Return Channel (ARC), 4096 x 2160 Capabilities, Extra Color Spaces, Ethernet Channel.



### Perfect Flexibility

This HDMI cable can withstand bend test of 50,000+ times without reducing cable flexibility and ensure the best performance possible.



### Durable Construction


The HDMI cable features MicroCoax technology and copper braid shielding that prevent interference and increase performance.



### Flawless Transmission

No screen flicker, black screen and snowflake. Enjoy a crystal-clear TV sound quality while experiencing deep colors and high-resolution images



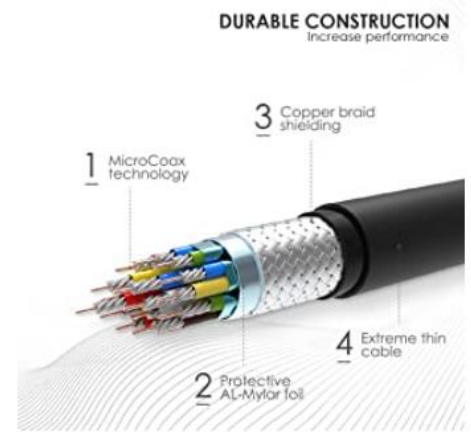

Perfect flexibility :

- Reliable & durable - from **Micro-Coax Technology**
- **50,000+** bend lifespan make it extraordinary durability.

Strong anti-interference :

- Avoid flickering screen
- Stable transmission

Durable construction :

- Built to be flexible, lightweight, and durable
- Increase performance.



Universal Compatibility :

- HDMI Ethernet channel
- Audio Return Channel
- 3D Support
- 4096 x 2160 Capabilities
- Extra Color Spaces

Give You More Possibilities :

- Mirror Mode: The two screens display the same picture, good helper for meetings
- Extended Mode: Multi-task split screen operation, one work, one entertainment, to solve your different needs

4K UHD Transmission :

- Enjoy immediate connectivity and sharp picture quality with the Nanosecond 4K HDMI Cable.



Cable Type	Standard HDMI to Standard HDMI	Micro HDMI to Standard HDMI	Mini HDMI to Standard HDMI	Micro HDMI to Mini HDMI	Standard HDMI to Standard HDMI	Micro HDMI to Standard HDMI
Length	2.6ft (0.8m)	2.6ft (0.8m)	2.6ft (0.8m)	2.6ft (0.8m)	6ft (1.8m)	6ft (1.8m)
Resolution	4K 60Hz	4K 60Hz	4K 60Hz	4K 60Hz	4K 60Hz	4K 60Hz