

2

1


NOTES:

- 1. IDENTIFICATION: ANALOG MAGNETIC DOOR SENSOR WITH RJ45 JACK
- 2. GENERAL APPEARANCE:
 COLOR
 BLACK

PART NUMBER	CABLE LENGTH
ZEDL06	500MM

3. PRODUCT SPECIFICATION:

- A. OPERATING TEMPERATURE: -40 C - 105 C
- B. MAX POWER: 10W
- C. SWITCHING VOLTAGE (MAX): 200VDC
- D. SWITCHING CURRENT (MAX): 0.5ADC
- E. CONTACT RESISTANCE (MAX): 200mOHM
- F. CONTACT TYPE: NORMALLY OPEN
- G. MAGNETIC SENSITIVITY:
 PULL-IN AT RANGE 27-33 AT
 ACTIVATE DISTANCE 9.0mm AVERAGE
- H. MAGNETIC SENSITIVITY DERATES WHEN MOUNTED ON STEEL

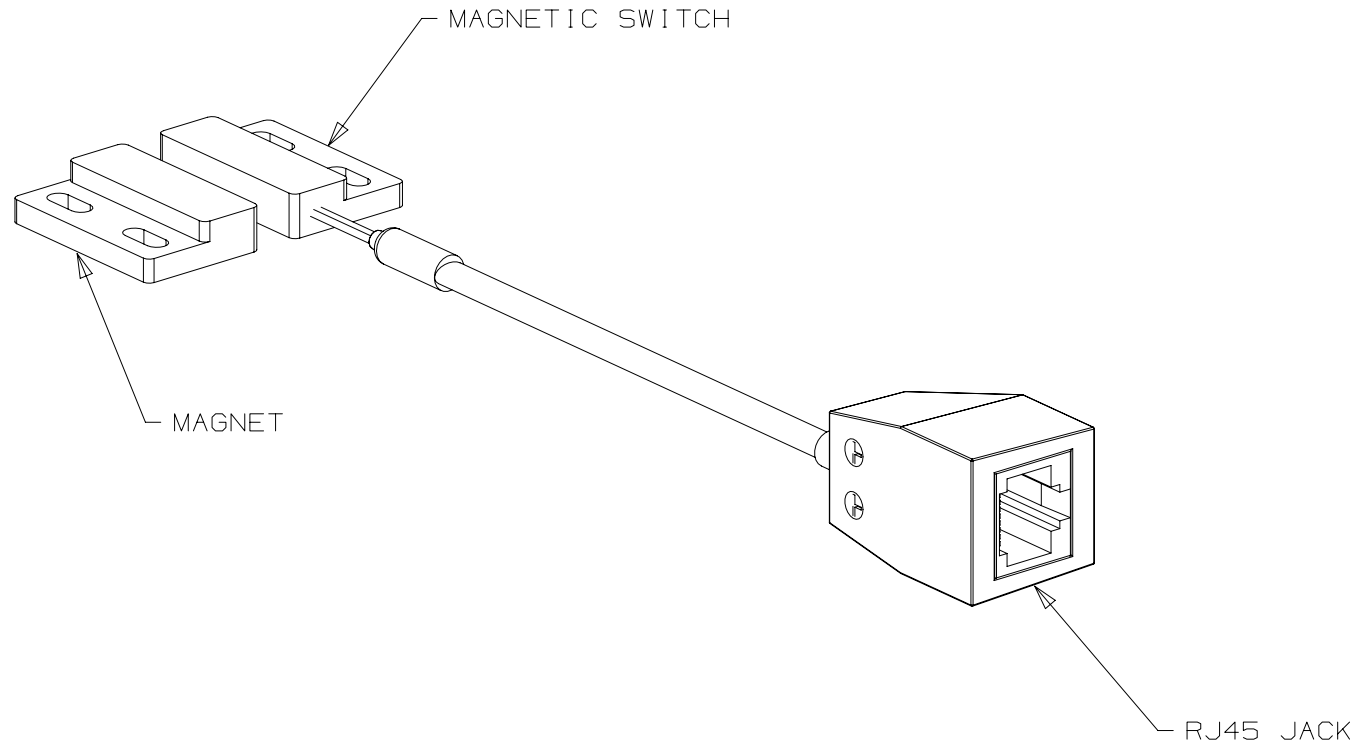

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
00A	05/09/2017	CSH		EDM	RELEASED TO PRODUCTION	14V125BA

TITLE		MAGNETIC DOOR SENSOR WITH RJ45 JACK	
ITEM REVISION NAME		CUSTOMER DRAWING	
DATASET FILE NAME		14V125BA/00	PANDUIT
		14V125BA_DC/00A	
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm]		MATERIAL: N/A	
.X ±	.XXX ±	DRAWING NUMBER: 14V125BA_DC	
.XX ±	ANGLES ±	THIRD ANGLE PROJECTION	
CSH	DATE: 05/09/2017	CHK	SCALE: NTS
SHT 1 OF 1		SIZE: B	

2

1

D10100DB/17