


IP67

03



- SA Series IP67
- Push-pull coupling

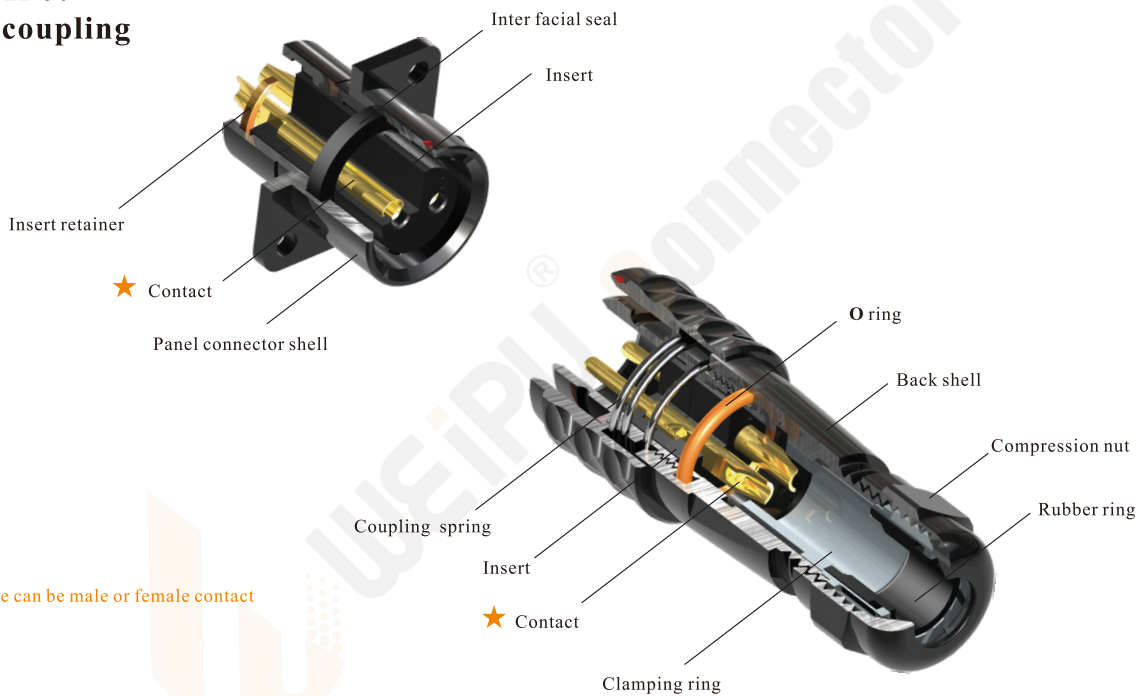

★ Each side can be male or female contact

Material and spec

Coupling	Push-pull
Shell material	Anodized aluminium
Insert material	PPS, max temperature 260 °C
Contact material	Brass with gold plating
Termination	Solder: SA6, SA8, SA10, SA12, SA16, SA20, SA24, SA28 Crimp: SA16, SA20, SA24, SA28 Screw: SA20, SA24, SA28
Cable outer diameter range	SA6: I:2-3mm, II:3-4mm SA12: I: 4-6.5mm , II: 5-8mm SA24:10-14mm SA8: I:3-4mm, II:4-5mm SA16: I: 5-8mm , II: 8-12mm SA28:I:9-13mm, II :13-16mm SA10:I:3-4mm, II:4-6.5mm SA20: I: 5-9mm, II: 8-12mm
IP rating	IP67
Mating cycle	500, USB:1000
Temperature range	-40°C ~ +85°C; SA24 Data: -20°C ~ +70°C
Insulation resistance	2000 MΩ

SA24 Series



SA24

03




HDMI2.0 Plug
Mate with SA2411, SA2412, SA2413

SA2410/PHDMI2.0

Wire length:
0.5m
1.0m
1.5m
2.0m
3.0m

Colour:
B: Black
S: Silver
L: Blue (special order)
G: Green (special order)
R: Red (special order)

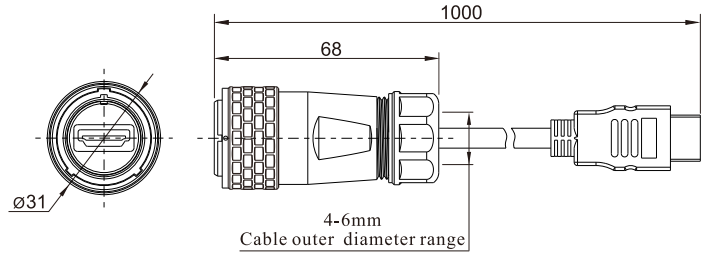


★ Wire length can be customized



HDMI2.0 Receptacle
Mate with SA2410

SA2411/SHDMI2.0

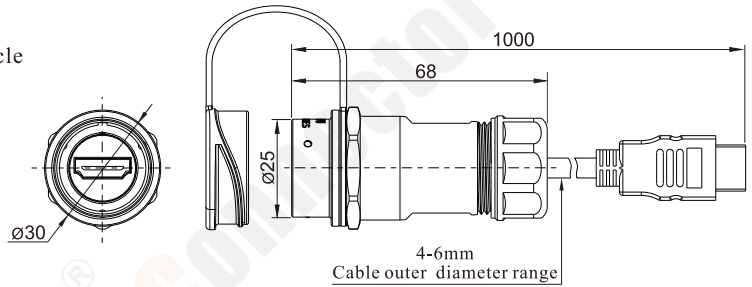


★ The cable length can be customized, but not more than 5 meters.



HDMI2.0 Rear-nut mount receptacle
Mate with SA2410

SA2412/SHDMI2.0

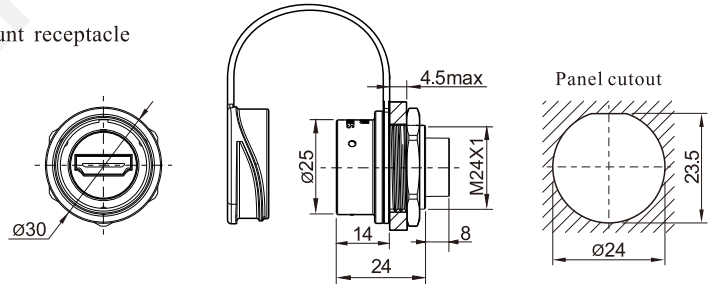

HDMI2.0 Square flange receptacle
Mate with SA2410

SA2413/SHDMI2.0

