




Tuning Fork Crystal


SMD-version

part no.	12.87118
model	KX - 327S
frequency	32.768 kHz
operating temperature	-20° ~ +70°C
frequency tolerance at +25°C	±20 ppm
temperature tolerance (parabolic coefficient)	-0.034 ±0.006 ppm/°C ² typ., -0.042 ppm/°C ² max.
turnover temperature	+25°C ± 5°C
load capacitance C _L	6 pF
series resistance R ₁ max.	50k Ohm
aging at +25°C (first year) max.	±3 ppm
shunt capacitance C ₀	0.9 pF typ.
drive level max.	0.001 mW
contents of reel	3000 pcs.


Dimensions:

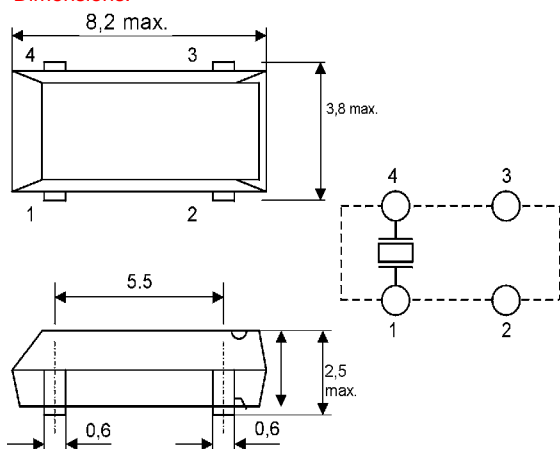

Reflow soldering condition:

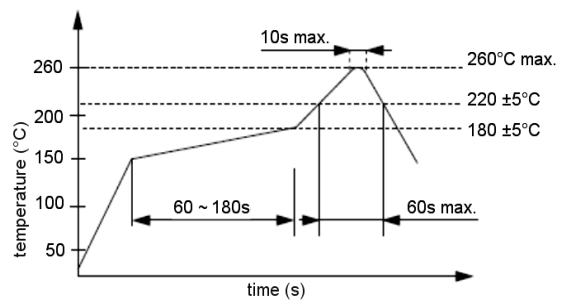

Tape specification:

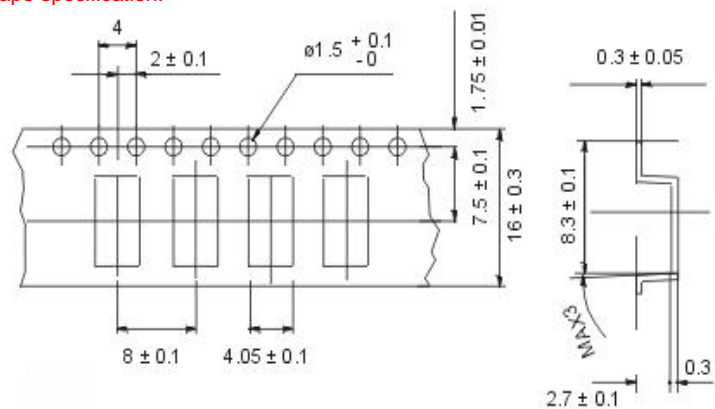

reel diameter 330 mm

Suggested soldering pad:

