


## **ANSI PFA Insulated Fine Gauge Exposed Junction Thermocouple (0.076mm conductors) - Type K**

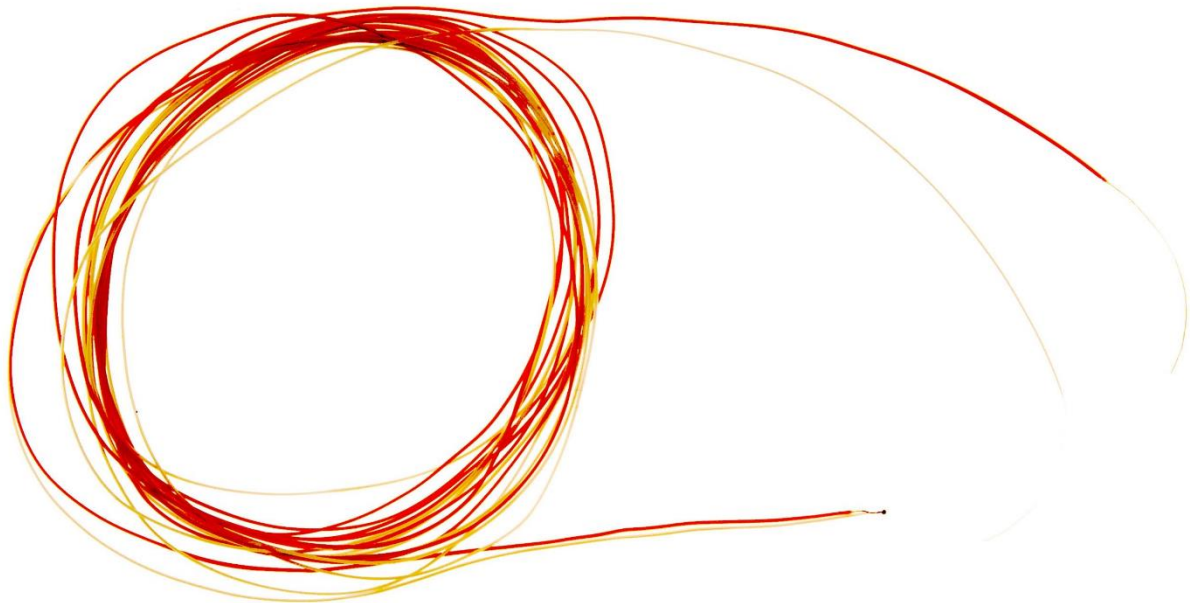

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

## Specifications

<b>General Description</b>	Fine Gauge Exposed Welded Tip Thermocouple
<b>Sensor Type</b>	Fast response, welded tip exposed junction
<b>Thermocouple Type</b>	K
<b>Thermocouple Junction</b>	Exposed
<b>Cable Length</b>	1m
<b>Cable Type</b>	Teflon® PFA insulated wires
<b>Core / Strands</b>	0.003" (0.076mm) conductors
<b>Cable Termination</b>	Bare tails
<b>Max. Temperature</b>	+260°C
<b>Min. Temperature</b>	-75°C
<b>Standards Met</b>	ANSI colour coded
<b>Manufacturers Code</b>	ANSI Fine Gge K 1m

## Ordering Information

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Number
K	TWIN TWISTED	PFA	0.076mm	1m (3.3ft)	FINE GAUGE ANSI	XE-2006-001