


Type K General Purpose Thermocouple Probe, Glassfibre insulated Cable with Stainless Steel Over-Braid Terminating in Bare tails - IEC

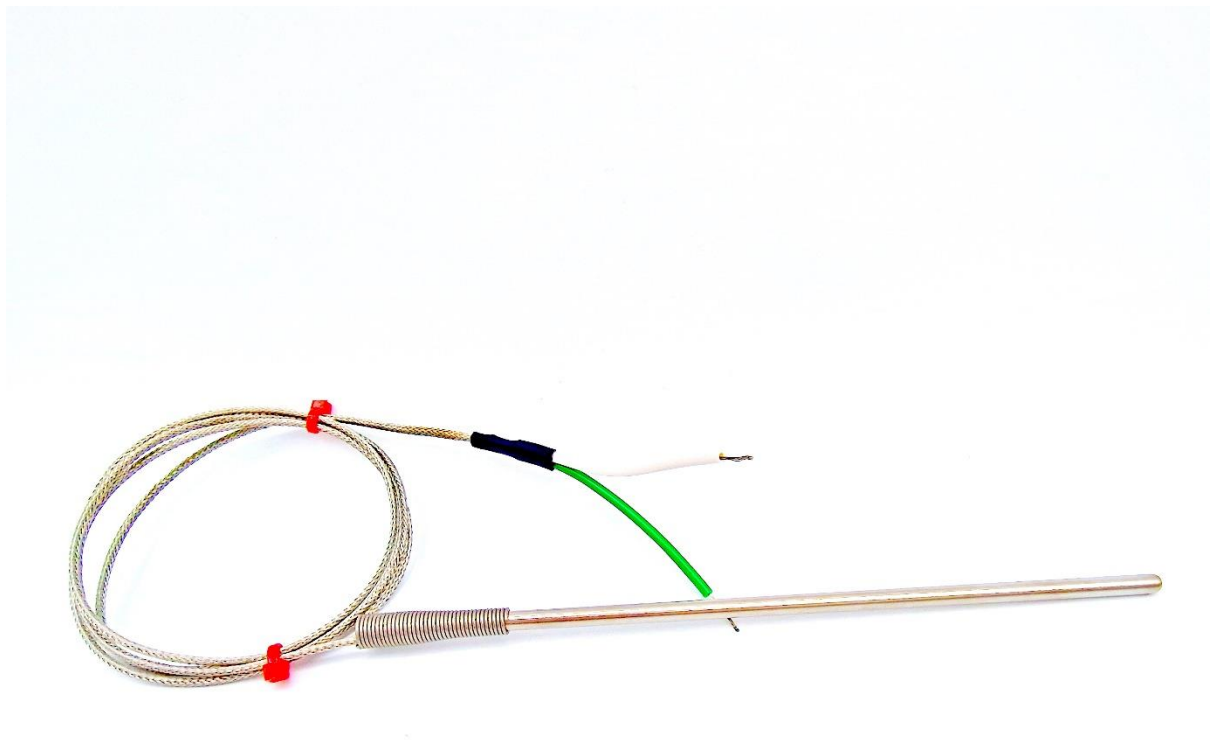

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Specifications

General Description	Rugged thermocouple with stainless steel sheath
Thermocouple Type	K
Thermocouple Junction	Grounded hot junction for fast response
Probe Diameter	4.5mm
Probe Length	150mm
Cable Length	2m
Cable Type	Glassfibre insulated lead with stainless steel overbraid
Core / Strands	7/0.2mm
Termination Type	Bare tails
Max. Temperature	+350°C
Min. Temperature	-60°C
Standards Met	IEC
Manufacturers Code	FAA-GSK-4.5-150-2.0-C4-T-I

Ordering Information

Type	Cable Length	Diameter x Length	Termination	Manufacturers Code	Manufacturers Order Code
K	2m	4.5 x 150mm	Bare Tails	FAA-GSK-4.5-150-2.0-C4-T-I	XE-3401-001