


IEC PTFE insulated Twin Twisted Exposed Junction Thermocouple with Miniature Plug - Type K

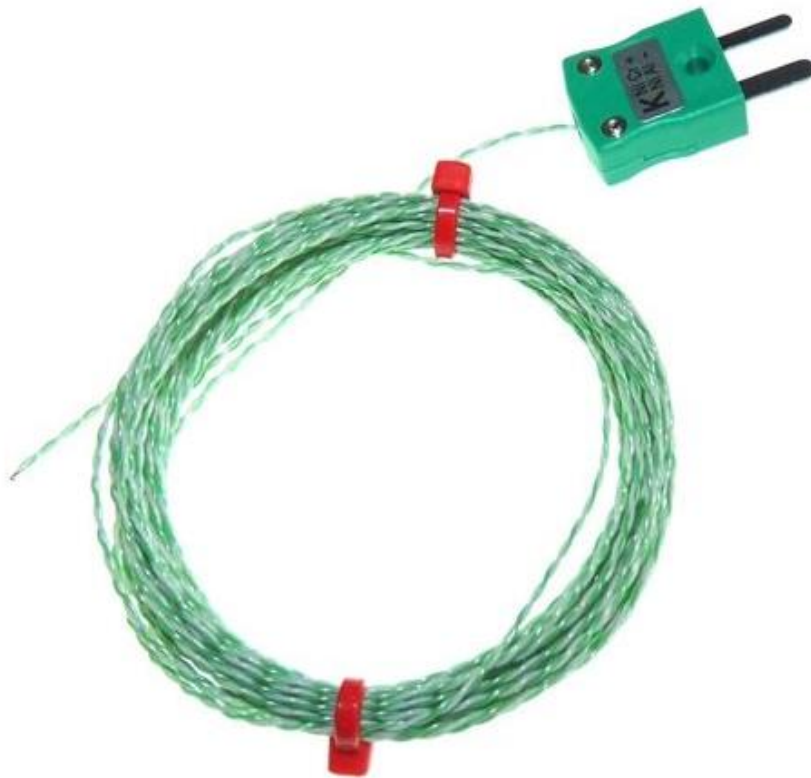

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Specifications

General Description	Fast response, welded exposed junction
Sensor Type	Exposed Junction
Thermocouple Type	K
Cable Length	1m
Cable Type	Teflon® PTFE insulated twin-twisted lead
Core / Strands	1/0.2mm
Termination Type	Miniature flat pin plug colour coded in accordance IEC 584 or bare tails
Max. Temperature	+260°C
Min. Temperature	-75°C
Tolerance	Class 1
Standards Met	IEC-584-3
Manufacturers Code	Z2-K-1/0.2mm-1m-MP

Ordering Information

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Number
K	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Miniature Plug	XE-3505-001