


ANSI PFA insulated Exposed Junction Thermocouple with Bare Tails - Type K

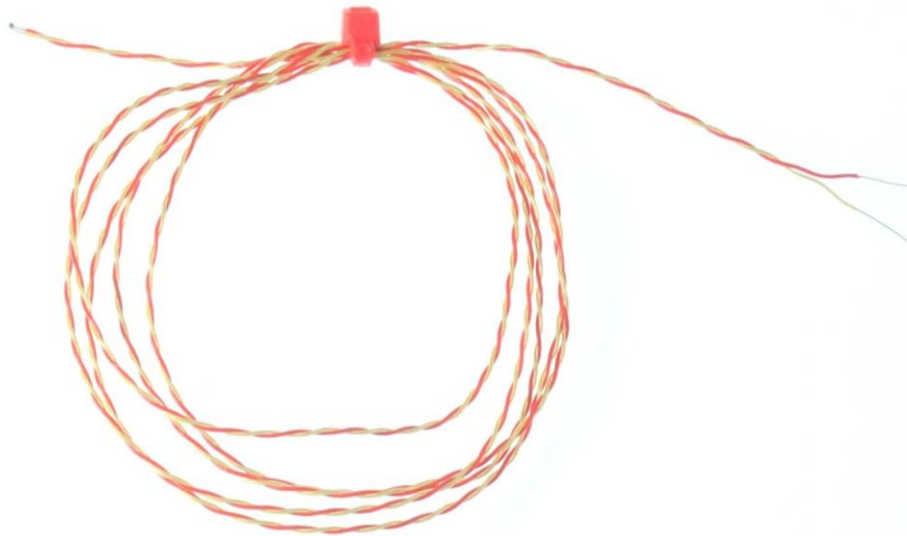

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Specifications

General Description	Fast response, welded exposed junction
Thermocouple Type	K
Thermocouple Junction	Exposed
Cable Length	2m
Cable Type	Teflon® PFA insulated twin-twisted lead
Core / Strands	1/0.2mm
Cable Termination	Bare wire
Max. Temperature	+250°C
Min. Temperature	-75°C
Standards Met	ANSI MC96.1
Manufacturers Code	Z2-K-2.0-1/0.2-T-ANSI

Ordering Information

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Order Number
K	TWIN TWISTED	PFA	1/0.2mm	2m (6.56ft)	Bare Tails	XE-3541-001