


## **ANSI PFA insulated Exposed Junction Thermocouple with Miniature Plug - Type K**

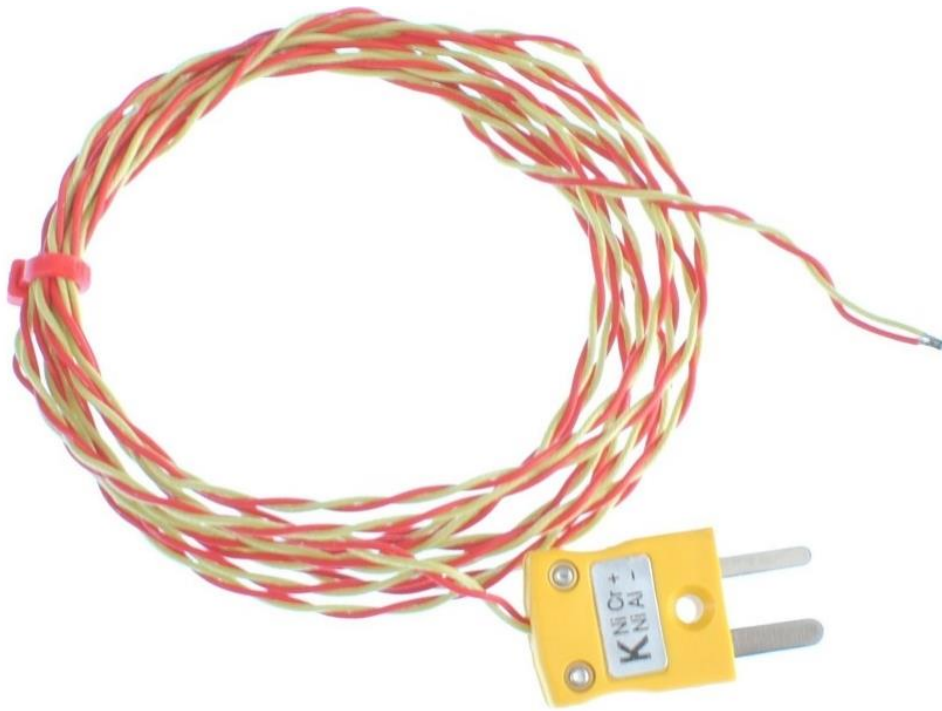

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple

## Specifications

<b>General Description</b>	Fast response, welded exposed junction
<b>Thermocouple Type</b>	K
<b>Thermocouple Junction</b>	Exposed
<b>Cable Length</b>	5m
<b>Cable Type</b>	Teflon® PFA insulated twin-twisted lead
<b>Core / Strands</b>	1/0.2mm
<b>Cable Termination</b>	Miniature Plug
<b>Max. Temperature</b>	+250°C
<b>Min. Temperature</b>	-75°C
<b>Standards Met</b>	ANSI MC96.1
<b>Manufacturers Code</b>	Z2-K-5.0-1/0.2-MP-ANSI

## Ordering Information

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Order Number
K	TWIN TWISTED	PFA	1/0.2mm	5m (16.4 ft)	Miniature Plug	XE-3559-001