

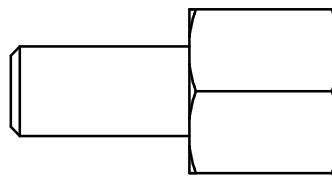


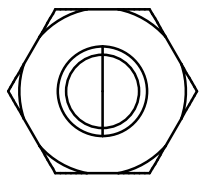

@ uk.essentracomponents.com
✉ orders@essentracomponents.co.uk

Contents

	Page
1 2D Views	2
2 Configuration settings	3
3 Contact information	4

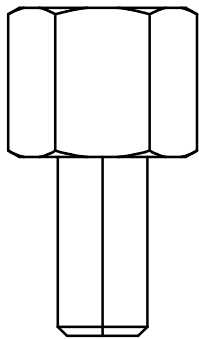

1 2D Views

2 Configuration settings

Configuration	
Part Number	CBMFTS205A
Description	Male To Female Standoff - Spacer Length 5 mm 0.197 in; Thread Length - 6 mm 0.236 in; Nylon 6/6
Material Flammability Standard	UL94 V-2
Full Material	Nylon 6/6
Spacer Shape	Hexagonal
Colour	Natural
Material	Nylon
Maximum Operating Temperature (Seed)	185 °F
Internal Thread Length (Seed)	0.118 in
Minimum Operating Temperature (Seed)	-40 °F
Thread Length (Seed)	0.236 in
Spacer Length (Seed)	0.197 in
Internal Thread Size	M3 x 0.5
Distance Across Flats (Seed)	0.217 in
Compatible Thread Sizes	M3 x 0.5

Bill of Materials Data	
Manufacturer	Essentra Components
Description	Male To Female Standoff - Spacer Length 5 mm 0.197 in; Thread Length - 6 mm 0.236 in; Nylon 6/6
Part Number	CBMFTS205A