

STATIC SOLUTIONS WITH SAVINGS

DISSIPATIVE RUBBER MAT
2 - LAYER T2



	Thickness	Top	Bottom	RTT	RTG
T2	.060"	<10 ⁹	<10 ⁶	10 ⁶ - 10 ⁸	10 ⁶ - 10 ⁸



Green 2-Layer ESD Rubber Mat

- B6223 2' x 3' mat w/hardware
- B6224 2' x 4' mat w/hardware
- B6225 2' x 5' mat w/hardware
- B62304 30" x 4' mat w/hardware

- B62250 2' x 50' roll
- B62350 3' x 50' roll
- B62450 4' x 50' roll
- B623050 30" x 50' roll

Blue 2-Layer ESD Rubber Mat

- B6123 2' x 3' mat w/hardware
- B6124 2' x 4' mat w/hardware
- B6125 2' x 5' mat w/hardware
- B61304 30" x 4' mat w/hardware

- B61250 2' x 50' roll
- B61350 3' x 50' roll
- B61450 4' x 50' roll
- B613050 30" x 50' roll

Features: Type T2 rubber table mats dual layer design provide excellent electricals and durability and will withstand hot solder and chemical abrasion. It exceeds both EOS/ESD and Department of Defense requirements. All pre-cut mats come with attached snap and one B9703 common point ground.

Gray 2-Layer ESD Rubber Mat

- B6423 2' x 3' mat w/hardware
- B6424 2' x 4' mat w/hardware
- B6425 2' x 5' mat w/hardware
- B64304 30" x 4' mat w/hardware

- B64250 2' x 50' roll
- B64350 3' x 50' roll
- B64450 4' x 50' roll
- B643050 30" x 50' roll

DISSIPATIVE RUBBER MAT
2 - LAYER T2+



	Thickness	Top	Bottom	RTT	RTG
T2+	.080"	<10 ⁹	<10 ⁶	10 ⁶ - 10 ⁸	10 ⁶ - 10 ⁸



Gray Premium 2-Layer ESD Mat

- B6623 2' x 3' mat w/hardware
- B6624 2' x 4' mat w/hardware
- B6625 2' x 5' mat w/hardware
- B66304 30" x 4' mat w/hardware

- B66240 2' x 40' roll
- B66340 3' x 40' roll
- B66440 4' x 40' roll
- B663040 30" x 40' roll

Green Premium 2-Layer ESD Mat

- B62823 2' x 3' mat w/hardware
- B62824 2' x 4' mat w/hardware
- B62825 2' x 5' mat w/hardware
- B628304 30" x 4' mat w/hardware

- B628240 2' x 40' roll
- B628340 3' x 40' roll
- B628440 4' x 40' roll
- B6283040 30" x 40' roll

Features: Type T2+ premium rubber table mats dual layer design provide excellent electricals and durability and will withstand hot solder and chemical abrasion. It exceeds both EOS/ESD and Department of Defense requirements. All pre-cut mats come with attached snap and one B9703 common point ground.

Blue Premium 2-Layer ESD Mat

- B6523 2' x 3' mat w/hardware
- B6524 2' x 4' mat w/hardware
- B6525 2' x 5' mat w/hardware
- B65304 30" x 4' mat w/hardware

- B65240 2' x 40' roll
- B65340 3' x 40' roll
- B65440 4' x 40' roll
- B653040 30" x 40' roll

DISSIPATIVE VINYL MAT
3 - LAYER TYPE Z



	Thickness	Top	Bottom	RTT	RTG
Z	.120"	<10 ⁷	<10 ⁸	10 ⁷ - 10 ⁸	10 ⁶ - 10 ⁸



Features: Botron's Type Z vinyl ESD table mats feature a unique three layer design, provide excellent electricals, and ergonomic comfort that only a foam back material can provide. It exceeds both EOS/ESD and Department of Defense requirements. All pre-cut mats come with attached snap and one B9703 common point ground.

Light Blue 3-Layer ESD Mat

- B4123 2' x 3' mat w/hardware
- B4124 2' x 4' mat w/hardware
- B4125 2' x 5' mat w/hardware
- B41304 30" x 4' mat w/hardware

- B41250 2' x 50' roll
- B41350 3' x 50' roll
- B41450 4' x 50' roll
- B413050 30" x 50' roll

**SEE PAGE 16 FOR
GROUNDING**



STATIC SOLUTIONS WITH SAVINGS

DISSIPATIVE RUBBER MAT
3 - LAYER T3

Blue ESD Mat

- B3123 2' x 3' mat w/hardware
- B3124 2' x 4' mat w/hardware
- B3125 2' x 5' mat w/hardware
- B31304 30" x 4' mat w/hardware

- B31250 2' x 50' roll
- B31350 3' x 50' roll
- B31450 4' x 50' roll
- B313050 30" x 50' roll

Gray ESD Mat

- B3423 2' x 3' mat w/hardware
- B3424 2' x 4' mat w/hardware
- B3425 2' x 5' mat w/hardware
- B34304 30" x 4' mat w/hardware

- B34250 2' x 50' roll
- B34350 3' x 50' roll
- B34450 4' x 50' roll
- B343050 30" x 50' roll

Green ESD Mat

- B3223 2' x 3' mat w/hardware
- B3224 2' x 4' mat w/hardware
- B3225 2' x 5' mat w/hardware
- B32304 30" x 4' mat w/hardware


- B32250 2' x 50' roll
- B32350 3' x 50' roll
- B32450 4' x 50' roll
- B323050 30" x 50' roll

Brown ESD Mat

- B3623 2' x 3' mat w/hardware
- B3624 2' x 4' mat w/hardware
- B3625 2' x 5' mat w/hardware
- B36304 30" x 4' mat w/hardware

- B36250 2' x 50' roll
- B36350 3' x 50' roll
- B36450 4' x 50' roll
- B363050 30" x 50' roll

BEST SELLER!

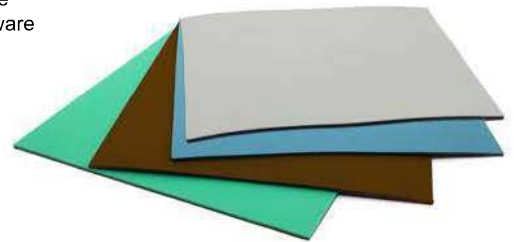

Features: Type T3 dissipative three layer rubber table mat is .120" thick. It is reversible with a static dissipative top, foam center and black conductive underside. It will not burn and is chemical resistant. 50' long rolls are available in widths of 2', 30", 3' and 4'. It is also available in many pre-cut sizes with grounding hardware and common point ground. Choose from Blue, Gray, Green, and Brown colors. All mats meet EOS/ESD standards.

	Thickness	Top	Bottom	RTT	RTG
T3	.120"	<10 ⁹	<10 ⁶	10 ⁶ - 10 ⁸	10 ⁶ - 10 ⁸

Blue ESD Mat

- B5123 2' x 3' mat w/hardware
- B5124 2' x 4' mat w/hardware
- B5125 2' x 5' mat w/hardware
- B5126 2' x 6' mat w/hardware
- B51304 30" x 4' mat w/hardware

- B51250 2' x 50' roll
- B513050 30" x 50' roll
- B51350 3' x 50' roll
- B51450 4' x 50' roll

- Solid vinyl construction
- Excellent electricals
- Reversible
- Easy to clean

Features: Type B+ mat is a solid vinyl design that provides excellent electricals and superior durability. Being constructed of solid vinyl means it's not only durable but it is also reversible. Type B+ exceeds both EOS/ESD and Department of Defense requirements. All pre-cut mats come with attached snap and one B9703 common point ground.

DISSIPATIVE VINYL MAT
TYPE B+



	Thickness	Top	Bottom	RTT	RTG
B+	.090"	<10 ⁷	--	10 ⁷ - 10 ⁸	10 ⁶ - 10 ⁸

Technical Operator Pad

- B5518 18" x 23" x 1/4" blue mat
- B55240 2' x 40' x 1/4" blue roll

Disk Drive Mat

- B5418 18" x 23" x 3/8" blue mat
- B543060 30" x 60' x 3/8" blue roll
- B54360 3' x 60' x 3/8" blue roll

- Available in 2 thicknesses
- Dissipative top layer
- Ergonomic
- Meets ANSI/EOS/ESD S20.20 Standards

Features: Type E Technical Operator Pad (TOP) and Type E+ Disk Drive Mat (DDM) are a soft vinyl foam material. TOP and DDM mats come in two thicknesses, 1/4" and 3/8" respectively, and provide comfort and can protect parts susceptible to physical shock and damage. They can be used on benches, carts, inside trays, shelves or to provide a static safe work area. No grounding is needed when used over a hard dissipative surface.

DISSIPATIVE VINYL FOAM
TYPE E/TYPE E+



	Thickness	Top	Bottom	RTT	RTG
E	1/4"	<10 ¹⁰	--	10 ⁸ - 10 ¹⁰	10 ⁸ - 10 ¹⁰
E+	3/8"	<10 ¹⁰	--	10 ⁸ - 10 ¹⁰	10 ⁸ - 10 ¹⁰



STATIC SOLUTIONS WITH SAVINGS

ANTI-FATIGUE FLOOR MATS
TYPE-SF



- Durable 1/2" conductive vulcanized rubber
- Tapered edge
- Domed surface for added comfort
- Non-slip design
- Available in black

Soft Foot Rubber Floor Mats
B4423 2' x 3' mat w/hardware
B4434 3' x 4' mat w/hardware

Features: Conductive Soft Foot floor mats are designed to add comfort to hard surfaces. These slip and soil resistant mats are 1/2" thick. They exceed both EOS/ESD and Department of Defense requirements. Available in pre-cut floor mats with molded edges. Does not include grounding hardware.

	Thickness	Top	Bottom	RTT	RTG
SF	1/2"	<10 ⁶	--	10 ⁵ - 10 ⁵	10 ⁵ - 10 ⁵

ANTI-FATIGUE FLOOR MATS
TYPE-DP



- Durable vinyl top layer
- Non-slip design
- Easy to clean
- Anti-fatigue backing
- Long lasting

9/16" Heavy Duty Anti-Fatigue Floor Mats
B4023HD 2' x 3' mat w/hardware
B4035HD 3' x 5' mat w/hardware
B40325HD 3' x 25' runner
B40375HD 3' x 75' runner
B40475HD 4' x 75' runner

1" Super Duty Anti-Fatigue Floor Mats
B4023SD 2' x 3' mat w/hardware
B4035SD 3' x 5' mat w/hardware
B40325SD 3' x 25' runner
B40375SD 3' x 75' runner
B40475SD 4' x 75' runner

Features: Type DP diamond plate vinyl mats and runners are designed to reduce strain from standing on hard surfaces. These slip and soil resistant mats are available with or without foam anti-fatigue backing. They exceed both EOS/ESD and Department of Defense requirements. Available in black runners, and pre-cut floor mats with molded edges and grounding hardware.

	Thickness	Top	Bottom	RTT	RTG
DP	HD - 9/16" SD - 1"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶

ANTI-FATIGUE FLOOR MATS
TYPE-CST



- Durable 1/8" vinyl top layer
- Energy absorbing
- Reduces strain
- Non-slip design
- Lead-free RoHS compliant

1/2" Heavy Duty Anti-Fatigue Floor Mats
B5723HD 2' x 3' mat w/hardware
B5735HD 3' x 5' mat w/hardware
B57325HD 3' x 25' runner
B57375HD 3' x 75' runner
B57475HD 4' x 75' runner

7/8" Super Duty Anti-Fatigue Floor Mats
B5723SD 2' x 3' mat w/hardware
B5735SD 3' x 5' mat w/hardware
B57325SD 3' x 25' runner
B57375SD 3' x 75' runner
B57475SD 4' x 75' runner

Features: Type CST smooth top vinyl mats and runners designed to reduce strain from standing on hard surfaces. These soil resistant mats are 1/8" thick, available with or without foam anti-fatigue backing. They exceed both EOS/ESD and Department of Defense requirements. Available in black runners, and pre-cut floor mats with molded edges and grounding hardware.

	Thickness	Top	Bottom	RTT	RTG
CST	HD - 1/2" SD - 7/8"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶



STATIC SOLUTIONS WITH SAVINGS

ANTI-FATIGUE FLOOR MATS
TYPE-VR

Type-VR Anti-Fatigue Floor Mats

- B7023** 2' x 3' mat w/hardware
- B7035** 3' x 5' mat w/hardware
- B70360** 3' x 60' runner
- B70460** 4' x 60' runner

- Durable 3/8" thick vinyl/foam construction
- Beveled edge
- Anti-fatigue design
- Pebble embossed surface texture



Features: Type VR anti-fatigue floor mats provide excellent electricals, and durability. It exceeds both EOS/ESD and Department of Defense requirements. Available in gray runners, and pre-cut floor mats with hardware.

	Thickness	Top	Bottom	RTT	RTG
VR	3/8"	<10 ¹⁰	--	<10 ¹⁰	<10 ¹⁰

ANTI-FATIGUE FLOOR MATS
TYPE-S

Type-S Anti-Fatigue Floor Mats

- BF435** 3' x 5' gray mat w/hardware
- BF335** 3' x 5' brown mat w/hardware
- BF436** 3' x 60' gray runner
- BF3360** 3' x 60' brown runner
- BF460** 4' x 60' gray runner



AVAILABLE IN THESE COLORS



Features: Type S vinyl anti-fatigue floor mats provide excellent electricals, and durability. It exceeds both EOS/ESD and Department of Defense requirements. Available in gray and brown runners, and pre-cut floor mats with hardware.

	Thickness	Top	Bottom	RTT	RTG
TS	3/8"	<10 ¹⁰	--	<10 ¹⁰	<10 ¹⁰

ANTI-FATIGUE FLOOR MATS
TYPE-EM

Type-EM Anti-Fatigue Floor Mats

- BEM220** 20" x 3' mat w/hardware
- BEM35** 3' x 5' mat w/hardware
- BEM36** 3' x 6' mat w/hardware
- BEM320** 3' x 20' runner

- Durable 5/8" thick sponge rubber construction
- Cross hatch surface texture
- Reduces strain
- Dissipative top layer



Features: Type EM Conductive Sponge rubber mats and runners designed to reduce strain from standing on hard surfaces. These slip and soil resistant mats are 5/8" thick with beveled edges on all sides. It exceeds both EOS/ESD and Department of Defense requirements. Available in black runners, and pre-cut floor mats with hardware.

	Thickness	Top	Bottom	RTT	RTG
EM	5/8"	<10 ⁶	--	10 ⁵ x 10 ⁶	10 ⁵ x 10 ⁶



STATIC SOLUTIONS WITH SAVINGS

ANTI-FATIGUE FLOOR MATS
TYPE-CRC



- Comfort anti-fatigue support
- Non-slip design
- Reduces strain
- Easy to clean

5/8" Heavy Duty Anti-Fatigue Floor Mats

- B4723HD** 2' x 3' mat w/hardware
- B4735HD** 3' x 5' mat w/hardware
- B47325HD** 3' x 25' runner
- B47375HD** 3' x 75' runner

1" Super Duty Anti-Fatigue Floor Mats

- B4723SD** 2' x 3' mat w/hardware
- B4735SD** 3' x 5' mat w/hardware
- B47325SD** 3' x 25' runner
- B47375SD** 3' x 75' runner

Features: Conductive CRC anti-fatigue floor mats and runners are designed to add comfort to hard surfaces. They feature a slip and soil resistant top and an anti-fatigue bottom that will reduce standing fatigue in the work environment. They exceed both EOS/ESD and Department of Defense requirements. Available in runners, and pre-cut floor mats with beveled edges and grounding hardware.

CRC	Thickness	Top	Bottom	RTT	RTG
	HD - 5/8"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶
	SD - 1"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶

FLOOR MATS
TYPE-F



- Durable 1/8" thick vinyl
- Dissipative top layer
- Non-slip design

Solid Vinyl Floor Mats

- BV435** 3' x 5' gray mat w/hardware
- BV4360** 3' x 60' gray runner
- BV4460** 4' x 60' gray runner

Features: V-Groove non-slip floor mats provide excellent electricals and durability. It exceeds both EOS/ESD and Department of Defense requirements. Available in Gray runners, and pre-cut floor mats with hardware.

TF	Thickness	Top	Bottom	RTT	RTG
	1/8"	<10 ¹⁰	--	<10 ¹⁰	<10 ¹⁰

FLOOR MATS
TYPE-DPM



- Durable 1/8" thick solid rubber
- Non-slip design
- Easy to clean

Solid Rubber Floor Mats

- B4223** 2' x 3' mat w/hardware
- B4235** 3' x 5' mat w/hardware
- B42325** 3' x 25' runner
- B42375** 3' x 75' runner
- B42475** 4' x 75' runner

Features: Type DPM diamond plate rubber mats and runners are slip and soil resistant mats, 1/8" thick and also available with or without 9/16" or 1" foam anti-fatigue backing (see p.11). They exceed both EOS/ESD and Department of Defense requirements. Available in Black runners, and pre-cut floor mats with molded edges and grounding hardware.

DPM	Thickness	Top	Bottom	RTT	RTG
	1/8"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶

FLOOR MATS
TYPE-CS



- Smooth top
- Easy to clean
- Soil resistant

Solid Rubber Floor Mats

- B4323** 2' x 3' conductive mat w/hardware
- B4335** 3' x 5' conductive mat w/hardware
- B43375** 3' x 75' conductive runner
- B43475** 4' x 75' conductive runner

Features: Type CS smooth top rubber mats and runners are soil resistant mats, 1/8" thick and also available with or without 1/2" or 7/8" foam anti-fatigue backing (see p.11). They exceed both EOS/ESD and Department of Defense requirements. Available in Black runners, and pre-cut floor mats with molded edges and grounding hardware.

CS	Thickness	Top	Bottom	RTT	RTG
	1/8"	<10 ⁶	--	10 ⁵ - 10 ⁶	10 ⁵ - 10 ⁶

