


**Connecting elements**  
**H35,0/39 BE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

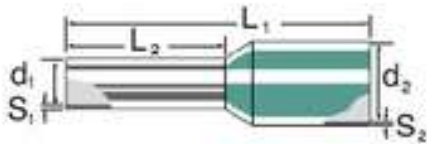

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

**General ordering data**

Type	H35,0/39 BE
Order No.	<a href="#">0317300000</a>
Version	Wire-end ferrule, insulated, 28 mm, 25 mm, beige
GTIN (EAN)	4008190151294
Qty.	50 pc(s).
Packaging	loose

## Connecting elements H35,0/39 BE

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Technical data

### Dimensions and weights

Width	39 mm	Width (inches)	1.535 inch
Net weight	1.75 g		

### Technical data

Version	insulated
---------	-----------

### Wire-end ferrules

Collar diameter (D2)	12.7 mm	Colour code	Weidmüller
Conductor cross-section	35 mm <sup>2</sup>	Contact surface diameter (D1)	8.3 mm
Contact surface length (L2)	25 mm	L1 in mm	39 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.4 mm
Stripping length	28 mm	Wire connection cross section AWG, max.	AWG 2

### Classifications

ETIM 3.0	EC000005	ETIM 4.0	EC000005
ETIM 5.0	EC000005	ETIM 6.0	EC000005
UNSPSC	31-16-31-02	eClass 5.1	27-40-02-01
eClass 6.2	27-40-02-01	eClass 7.1	27-40-02-01
eClass 8.1	27-40-02-01	eClass 9.0	27-40-02-01
eClass 9.1	27-40-02-01		

### Approvals

Approvals



ROHS Conform

### Downloads

Brochure/Catalogue	<a href="#">CAT 6 TOOLS 15/16 EN</a>
Engineering Data	<a href="#">EPLAN, WSCAD, Zuken E3.S</a>
Engineering Data	<a href="#">STEP</a>