

H35,0/18**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

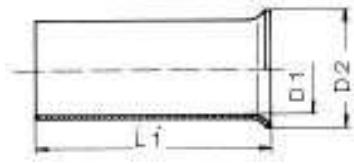

For conductors from 10.0 to 185.0 mm² (AWG 7 - 350 MCM)

tin-plated copper

dimensional tolerances to DIN 46228 part 1

- supplied loose in poly-bag

General ordering data

Order No.	0368900000
Type	H35,0/18
Version	Wire end ferrule, 35 mm ²
GTIN (EAN)	4008190145675
Qty.	100 pc(s).

H35,0/18

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data**Dimensions and weights**

Length	18 mm	Net weight	0.92 g
--------	-------	------------	--------

Product data

Conductor cross-section	35 mm ²	Wire connection cross section AWG, max.	AWG 2
Contact surface diameter (D1)	8.3 mm	Collar diameter (D2)	11 mm

Classifications

ETIM 2.0	EC000005	ETIM 3.0	EC000005
UNSPSC	31-16-31-02	eClass 4.1	27-06-07-01
eClass 5.1	27-40-02-01	eClass 6.0	27-40-02-01
eClass 7.0	27-40-02-01		

Product information

Description of article	Wire end ferrule without plastic collar
------------------------	-----------------------------------------

Approvals

Approvals

