


**Cabtite (cable entry system)  
CABTITE FRL 10/6 BK**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

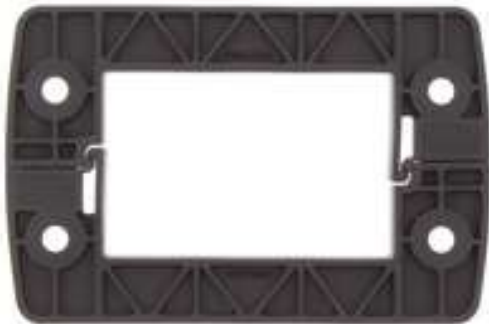

The frame, fabricated from a single piece, is quick and easy to assemble and consists of dimensionally stable, fibre-glass reinforced plastic. The captive foamed seal guarantees effective IP66 sealing in accordance with DIN EN 60529, even on painted and rough surfaces.

**General ordering data**

Type	CABTITE FRL 10/6 BK
Order No.	<a href="#">2584240000</a>
Version	Cable entry systems, Cabtite (cable entry system), Polyamide, glass fibre-reinforced, Deep black, Height: 11.3 mm, Width: 68.8 mm, Depth: 11.3 mm, -40 °C...120 °C
GTIN (EAN)	4050118616231
Qty.	10 pc(s).

**Cabtite (cable entry system)  
CABTITE FRL 10/6 BK**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data****Dimensions and weights**

Length	105 mm	Length (inches)	4.134 inch
Width	68.8 mm	Width (inches)	2.709 inch
Height	11.3 mm	Height (inches)	0.445 inch
Height of lowest version	11.3 mm	Depth	11.3 mm
Depth (inches)	0.445 inch	Mounting dimension - width	32 mm
Mounting dimension - height	83 mm	Net weight	27.6 g
Diameter	5.5 mm		

**General information**

Tightening torque	3 Nm	Opening width	40 mm
Opening length	62.8 mm	UL 94 flammability rating	V-0
Halogen	No	Silicone	No
Material	Polyamide, glass fibre-reinforced		

**Classifications**

ETIM 6.0	EC002624	eClass 6.2	27-14-92-01
eClass 9.1	27-18-92-65		

**Approvals**

Approvals



ROHS Conform

**Downloads**User Documentation [CabTite Installation Instructions](#)