


## Five Arm (Star) Clamping Knobs

### Series #2980

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

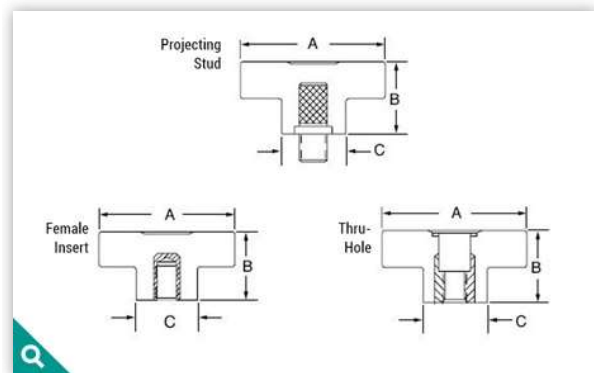

CHECK INVENTORY

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
2980	2.25	0.78	0.84	Thermoplastic	1/4-20	Thru-Hole		BLACK	<a href="#">Download</a>
2980-A	2.25	0.78	0.84	Thermoplastic	5/16-18	Thru-Hole		BLACK	<a href="#">Download</a>
2980-B	2.25	0.78	0.84	Thermoplastic	3/8-16	Thru-Hole		BLACK	<a href="#">Download</a>
2980-C	2.25	0.78	0.84	Thermoplastic	3/8-24	Thru-Hole		BLACK	<a href="#">Download</a>
2980-E	2.25	0.78	0.84	Thermoplastic	5/16-18	Projecting Stud	0.75	BLACK	<a href="#">Download</a>
2980-F	2.25	0.78	0.84	Thermoplastic	3/8-16	Thru-Hole		BLACK	<a href="#">Download</a>
2980-P	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	1	BLACK	<a href="#">Download</a>
2980-S	2.25	0.78	0.84	Thermoplastic	3/8-16	Thru-Hole		BLACK	<a href="#">Download</a>
2980-U	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	1.5	BLACK	<a href="#">Download</a>
2980-W	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	1.75	BLACK	<a href="#">Download</a>
2980-X	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1	BLACK	<a href="#">Download</a>
2980AA	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	1.25	BLACK	<a href="#">Download</a>
2980AC	2.25	0.78	0.84	Thermoplastic	1/4-20	Female Insert	0.375	BLACK	<a href="#">Download</a>
2980AD	2.25	0.78	0.84	Thermoplastic	5/16-18	Female Insert	0.50	BLACK	<a href="#">Download</a>
2980AE	2.25	0.78	0.84	Thermoplastic	3/8-16	Female Insert	0.50	BLACK	<a href="#">Download</a>
2980AH	2.25	0.78	0.84	Thermoplastic	3/8-24	Thru-Hole		BLACK	<a href="#">Download</a>
2980AK	2.25	0.78	0.84	Thermoplastic	1/4-20	Thru-Hole		BLACK	<a href="#">Download</a>
2980AL	2.25	0.78	0.84	Thermoplastic	5/16-18	Thru-Hole		BLACK	<a href="#">Download</a>
2980AP	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1.75	BLACK	<a href="#">Download</a>

2980AF	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1.5	BLACK	<a href="#">Download</a>
2980AS	2.25	0.78	0.84	Thermoplastic	5/16-18	Thru-Hole		BLACK	<a href="#">Download</a>
2980AU	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	0.50	BLUE	<a href="#">Download</a>
2980BA	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	2.25	BLACK	<a href="#">Download</a>
2980BB	2.25	0.78	0.84	Thermoplastic	5/16-18	Projecting Stud	1	BLACK	<a href="#">Download</a>
2980BD	2.25	0.78	0.84	Thermoplastic	5/16-18	Projecting Stud	0.75	WHITE	<a href="#">Download</a>
2980BE	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1.5	BLACK	<a href="#">Download</a>
2980BM	2.25	0.78	0.84	Thermoplastic	3/8-16	Projecting Stud	1	BLACK	<a href="#">Download</a>
2980BN	2.25	0.78	0.84	Thermoplastic	3/8-16	Female Insert	0.50	WHITE	<a href="#">Download</a>
2980BP	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1	BLACK	<a href="#">Download</a>
2980BQ	2.25	0.78	0.84	Thermoplastic	1/4-20	Thru-Hole		GREEN	<a href="#">Download</a>
2980BR	2.25	0.78	0.84	Thermoplastic	5/16-18	Thru-Hole		BLACK	<a href="#">Download</a>
2980BT	2.25	0.78	0.84	Thermoplastic	1/4-20	Projecting Stud	1.5	BLACK	<a href="#">Download</a>
2980BU	2.25	0.78	0.84	Thermoplastic	5/16-18	Projecting Stud	0.75	BLACK	<a href="#">Download</a>
2980BY	2.25	0.78	0.84	Thermoplastic	5/16-18	Projecting Stud	1.5	BLACK	<a href="#">Download</a>
2980CG	2.25	0.78	0.84	Thermoplastic	M6	Female Insert		BLACK	
2980CW	2.25	0.78	0.84	Thermoplastic	M8	Female Insert		BLACK	
2980CX	2.25	0.78	0.84	Thermoplastic	M6	Projecting Stud		BLACK	
2980CY	2.25	0.78	0.84	Thermoplastic	M6	projecting Stud		BLACK	
2980CZ	2.25	0.78	0.84	Thermoplastic	M8	Projecting Stud		BLACK	
2980DA	2.25	0.78	0.84	Thermoplastic	M8	Projecting Stud		BLACK	

#### PRODUCTS

[Knobs](#)  
[Handles](#)  
[Electronic Enclosures](#)  
[Hex Hybrid Standoffs](#)  
[Two-Shot / Soft Touch](#)  
[Frac Balls](#)  
[Cable Glands](#)  
[Rubber Grommets](#)  
[Custom Molding](#)

#### RESOURCES

[Engineering Specifications](#)  
[Distributor Listing](#)  
[Sales Representative Listing](#)

#### COMPANY

[About Us](#)  
[Capabilities](#)  
[Certifications](#)  
[Contact Us](#)  
[Blog](#)  
[Careers](#)

#### QUESTIONS ?






1 + 1 =  \*