

DKS-CRIMP-T1-ND


Professional All-Purpose Crimping | Hand Tool with Dies

Product highlights:

- Easy Handling
- Ratchet Release
- Ergonomic design

Specifications:

Length:	Approx. 220 mm
Width:	Approx. 80 mm
Depth:	Approx. 24 mm
Weight:	Approx. 510 grams
Packaging:	Box

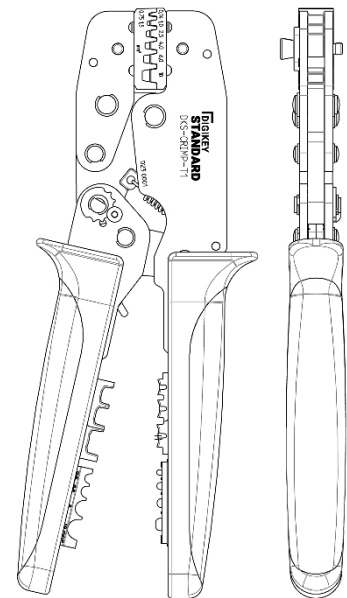

Conforms to the following industry standards:

ROHS Compliant	Yes
----------------	-----

Die compatibility

DIE PART NUMBER	APPLICATION RANGE	CROSS SECTION
DKS-DIE-1	Wire end ferrules with or without plastic shroud acc. to DIN 46228	0.14-10 mm ²
DKS-DIE-2	Red/blue/yellow DIN cable lugs, pin cable lugs, tabs and receptacles, circular connectors and receptacles, and butt and parallel connectors.	Red: 0.5-1.5 mm ² / AWG 20 – 16 Blue: 1.5-2.5 mm ² / AWG 16 – 14 Yellow: 4.0-6.0 mm ² / AWG 12 – 10
DKS-DIE-3	Non-insulated cable lugs, closed barrel	0.1-10 mm ² / AWG 26 – 8
DKS-CRIMP-T1	Crimp tool with DKS-DIE-1, DKS-DIE-2, and DKS-DIE-3	