



For the latest products,
information, innovations and
solutions, go to
bannerengineering.com

P/N 178074

Banner Engineering Corp.

9714 Tenth Avenue North
Minneapolis, Minnesota 55441
763-544-3164 • 1-888-373-6767
www.bannerengineering.com



more sensors, more solutions



2014

Euro QD

See page 922

Length	Threaded 12-Pin (Open Shield)	
	Straight	Right-Angle
1.83 m	MQDC2S-1206	MQDC2S-1206RA
4.57 m	MQDC2S-1215	MQDC2S-1215RA
9.14 m	MQDC2S-1230	MQDC2S-1230RA
15.2 m	MQDC2S-1250	MQDC2S-1250RA

USB (BCR models)

See page 919

Length	8-Pin Euro QD to USB		4-Pin Pico QD to USB
	Used with Integrated Touch Screen Models		Remote Touch Screen
	Straight	Right-Angle	Straight
0.15 m	MQDEC-8005-USB	MQDEC-8005RA-USB	PSG-4M-4005-USB
0.30 m	MQDEC-801-USB	MQDEC-801RA-USB	PSG-4M-401-USB
0.90 m	MQDEC-803-USB	MQDEC-803RA-USB	PSG-4M-403-USB
3.00 m	MQDEC-810-USB	MQDEC-810RA-USB	PSG-4M-410-USB

USB (BCR Plus models)

See page 907

Length	4-Pin Pico QD to USB	
	Straight	
0.15 m		PSG-4M-4005-USB
0.30 m		PSG-4M-401-USB
0.90 m		PSG-4M-403-USB
3.00 m		PSG-4M-410-USB

Ethernet Communication (Plus only)

See page 933

Length	RJ45 to 4-Pin Pico QD	
	Straight	
2.00 m		IVUC-E-406
5.00 m		IVUC-E-415
9.00 m		IVUC-E-430
16.00 m		IVUC-E-450
23.00m		IVUC-E-475

iVu BCR & iVu Plus BCR

See page 880

See page 880

See page 879


See page 880

SMBIVURAL*	SMBIVURAR*	SMBIVUB	SMBIVUU

* For orientation see page 880.


Power

Select one

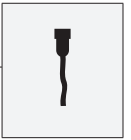


USB

Select one

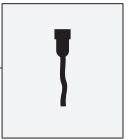


Ethernet

Plus only

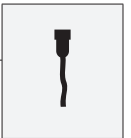

Mounting

 Select one



8-Pin Threaded M12/Euro-Style Splitter Cordsets—Flat Junction

Cable: PVC jacket, PUR (polyurethane) connector body, nickel-plated brass coupling nut
Conductors: 22 AWG, gold-plated contacts
Voltage/Current Rating: 60 V ac/75 V dc, 2.0 A
Temperature: -40° to +105° C **Environmental Rating:** IP68
Wiring: Parallel wired Y-cord

Connections					
Model	Branches (Female)	Trunk (Male)	Cable Diameter	Pinout	Used With
CSB-M1280M1280	No branches	No trunk	6.00 mm	<p>Female</p> <p>Male</p> <p>1 = Brown 5 = Black 2 = Or/Bk 6 = Blue 3 = Orange 7 = Gn/Ye 4 = White 8 = Violet</p>	<ul style="list-style-type: none"> EZ-ARRAY EZ-LIGHT Indicator Lights EZ-SCREEN w/8-pin QD (14 & 30 mm Resolution) EZ-SCREEN LP w/8-pin QD (14 & 25 mm Resolution) EZ-SCREEN w/8-pin QD (Point & Grid) EZ-SCREEN Type 2 AC Interface Boxes
CSB-M1281M1281	2 x 0.3 m	0.3 m			
CSB-M1288M1281		2.5 m			
CSB-M12815M1281		4.6 m			
CSB-M12825M1281		7.6 m			
CSB-UNT825M1281*		7.6 m Untermated			
Dimensions (mm)					

* Standard cordsets are yellow PVC with black overmold. For black PVC and overmold, add suffix **B** to model number (example, **CSB-M1280M1280B**).

8-Pin Threaded M12/Euro-Style to USB Cordsets—Double Ended

Cable: PVC jacket, PUR (polyurethane) connector body, nickel-plated brass coupling nut on Euro QD end
Conductors: 28 AWG or 24 AWG, gold-plated contacts
Voltage Rating: 60 V ac/75 V dc
Temperature: -40° to +90° C

Style	Length	Model	Cable Diameter	Dimensions (mm)	Pinout	Used With
Straight Euro QD/USB	0.15 m	MQDEC-8005-USB	4.80 mm		<p>USB</p>	<ul style="list-style-type: none"> iVu TG & BCR—Integrated Touch Screen models
	0.30 m	MQDEC-801-USB				
	0.90 m	MQDEC-803-USB				
	3.00 m	MQDEC-810-USB				
Right-Angle Euro QD/USB	0.15 m	MQDEC-8005RA-USB	4.80 mm		<p>Male</p>	
	0.30 m	MQDEC-801RA-USB				
	0.90 m	MQDEC-803RA-USB				
	3.00 m	MQDEC-810RA-USB				