

ARCA 203015



Sample image

Order symbol : ARCA 203015

Product nr : 8120020

UL Code : UL508A

Description : Cabinet, PC




Remarks : Grey cover, 1-point locking, hinges on the short side

EAN : 6418074079312

El. number :

- Finland : 3423117
- Denmark : 8212091184
- Sweden : 2500109

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

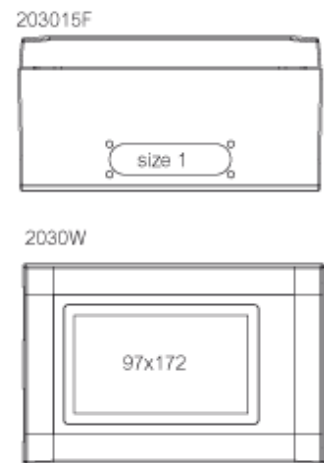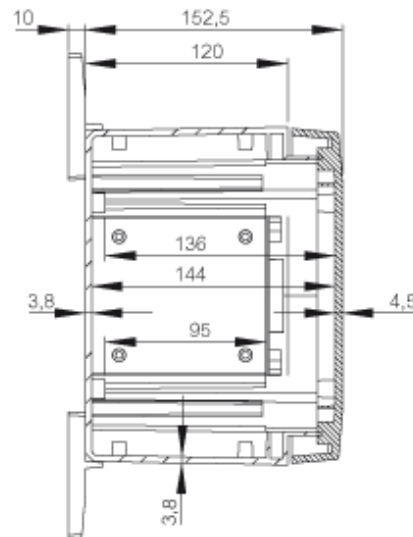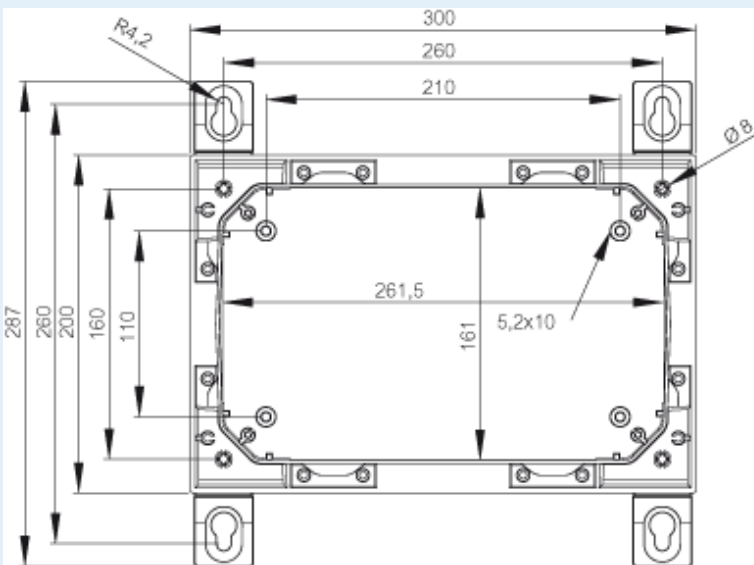

Dimensions :	Height	Width	Depth
mm :	200	300	150
inch :	7.87	11.81	5.91

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey

Accessories :

MPMP ARCA 3020	Mounting plate multiperforated (250x150x2 mm - ø3.6 mm)
IDS ARCA 2030	Inner door set
MPP ARCA 2030	Mounting plate perforated (250x150x2 mm - 26x11 mm)
MPS ARCA 3020	Mounting plate (250x150x2 mm) (250 x 150 x 2)
DRS ARCA 203015	DIN rail frame set (285 x 185 x 35)

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

RCS ARCA
2030

Rain canopy set for size 2030

PMK ARCA 30

PoleMounting kit, for pole ø100-300mm
(385 x 285 x 35)

MPX ARCA
3020

Mounting plate (250x150 mm)
(250 x 150 x 15)

Ratings :

Ingress protection (EN 60529): IP66;

Impact Resistance (EN 62262): IK10;

electrical_insulation : Totally insulated

Halogen free (DIN/VDE 0472, Part
815) : Yes

UV resistance : UL 746C

Flammability Rating : UL 94 5VA

Glow Wire Test (IEC 695-2-1) °C : 960C

UL Type NEMA__1_4_4X_12_13

Certificates :

Certificate FI 40467