

ARCA 302015



Sample image

Order symbol : ARCA 302015

Product nr : 8120002

UL Code : UL508A

Description : Cabinet, PC


Remarks : Grey cover, 1-point locking, hinges on the long side

EAN : 6418074079138

El. number :

- Finland : 3423044
- Denmark : 8212091003
- Sweden : 2500110

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

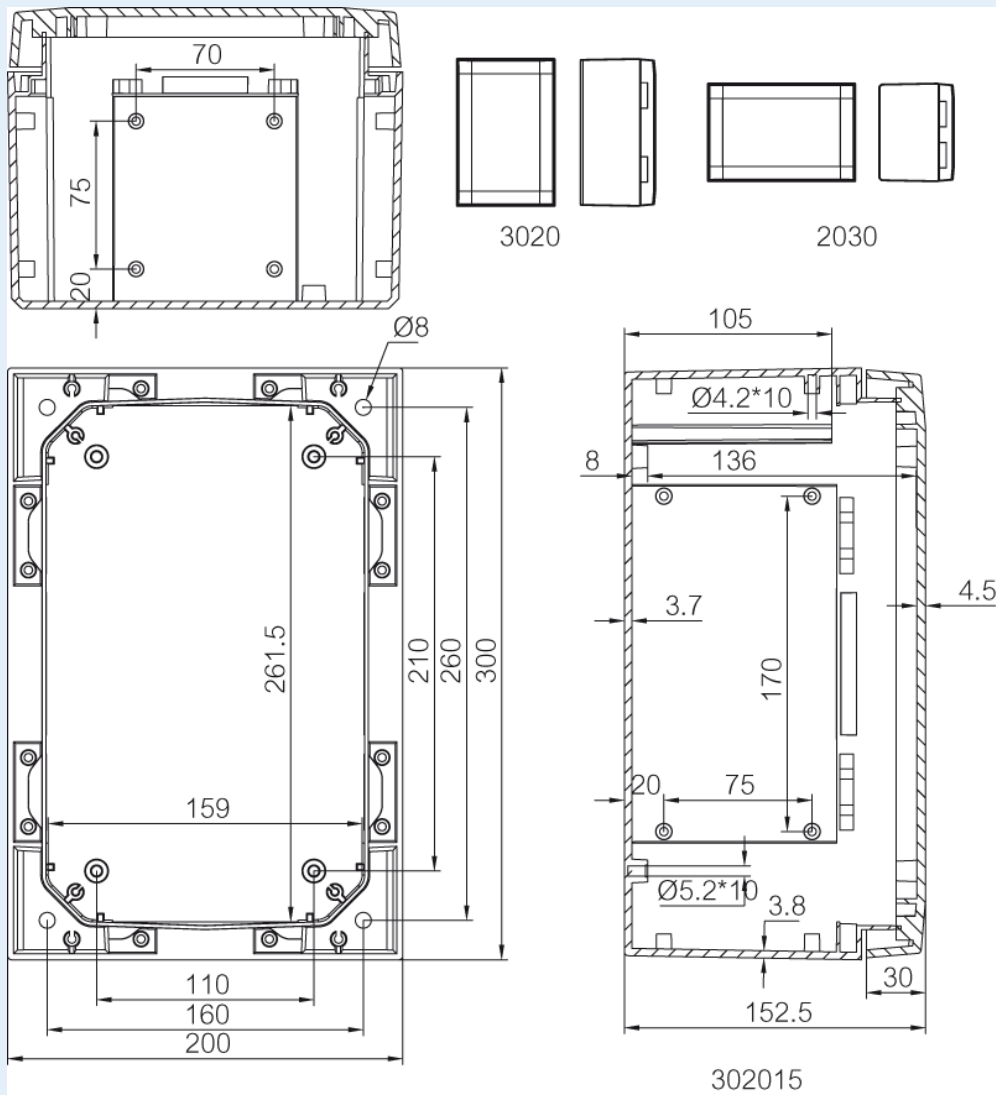

302015

Dimensions :

	Height	Width	Depth
mm :	300	200	150
inch :	11.81	7.87	5.91

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

MPP ARCA 3020	Mounting plate perforated (250x150x2 mm - 26x11 mm) (250 x 150 x 2)
DRS ARCA 302015	DIN rail frame set (285 x 185 x 35)
MPMP ARCA 3020	Mounting plate multiperforated (250x150x2 mm - ø3.6 mm)
PMK ARCA 20	PoleMounting kit, for pole ø100-300mm (385 x 285 x 35)
RCS ARCA 3020	Rain canopy set for size 3020
MPS ARCA 3020	Mounting plate (250x150x2 mm) (250 x 150 x 2)
IDS ARCA 3020	Inner door set (285 x 185 x 35)
MPX ARCA 3020	Mounting plate (250x150 mm) (250 x 150 x 15)

Ratings :

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated

Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C
UL Type	NEMA__1_4_4X_12_13

Certificates :

Certificate FI 40467