

ARCA 304021



Sample image

Order symbol : ARCA 304021

Product nr : 8120023

UL Code : UL508A

Description : Cabinet, PC




Remarks : Grey cover, 2-point locking, hinges on the short side

EAN : 6418074079343

El. number :

- Finland : 3423120
- Denmark : 8212091210
- Sweden : 2500113

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

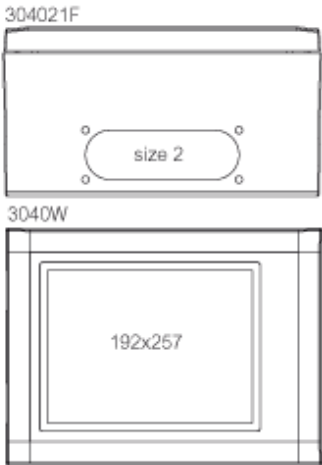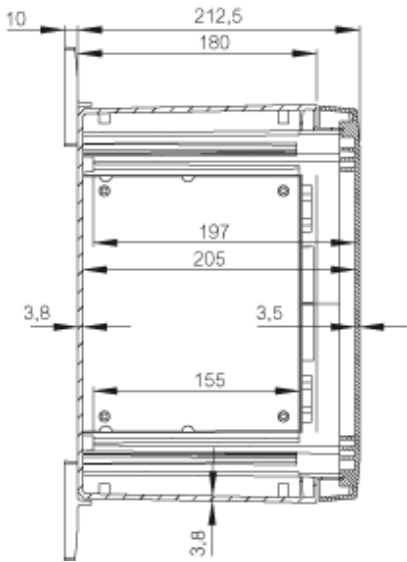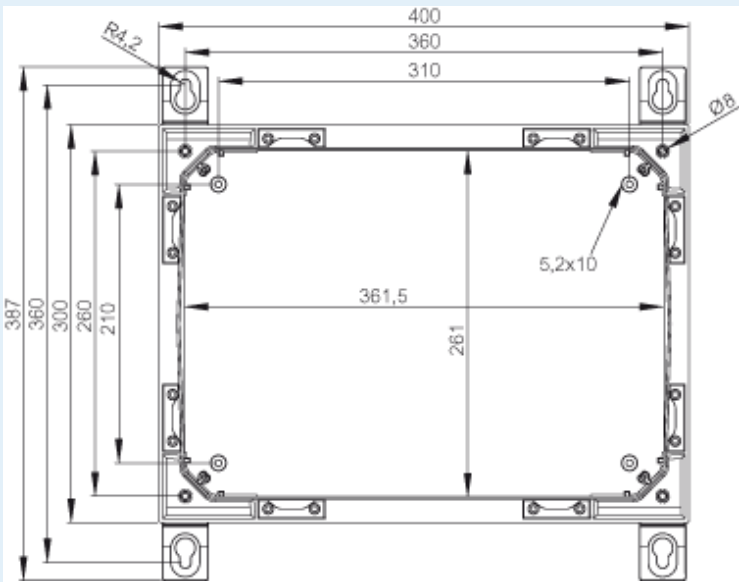

Dimensions :	Height	Width	Depth
mm :	300	400	210
inch :	15.75	11.81	8.27

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035

Accessories :

DRS ARCA 304021	DIN rail frame set (385 x 285 x 35)
DSP ARCA HRS	Door stopper ARCA, horizontal, right, small
DSP ARCA HLS	Door stopper ARCA, horizontal, left, small
IDS ARCA 3040	Inner door set
RCS ARCA	Rain canopy set for size 3040

Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :		
Temperature °C (continuous) :	-40 ... 80	
Temperature °F (continuous) :	-40 ... 175	

3040	
PMK ARCA 40	PoleMounting kit, for pole ø100-300mm (385 x 285 x 35)
MPP ARCA 3040	Mounting plate perforated (350x250x2 mm - 26x11 mm)
MPMP ARCA 4030	Mounting plate multiperforated (350x250x2 mm - ø3.6 mm)
MPS ARCA 4030	Mounting plate (350x250x2 mm) (350 x 250 x 2)
MPX ARCA 4030	Mounting plate (350x250 mm) (350 x 250 x 15)

Ratings :		
Ingress protection (EN 60529):	IP66;	
Impact Resistance (EN 62262):	IK10;	
electrical_insulation :	Totally insulated	
Halogen free (DIN/VDE 0472, Part 815) :	Yes	
UV resistance :	UL 746C	
Flammability Rating :	UL 94 5VA	
Glow Wire Test (IEC 695-2-1) °C :	960C	
UL Type	NEMA__1_4_4X_12_13	

Certificates :		
Certificate FI 40467		