

ARCA 406021



Sample image

Order symbol : ARCA 406021

Product nr : 8120026

UL Code : UL508A

Description : Cabinet, PC


Remarks : Grey cover, 2-point locking, hinges on the short side

EAN : 6418074079374

El. number :

- Finland : 3423124
- Denmark : 8212091249
- Sweden : 2500117

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

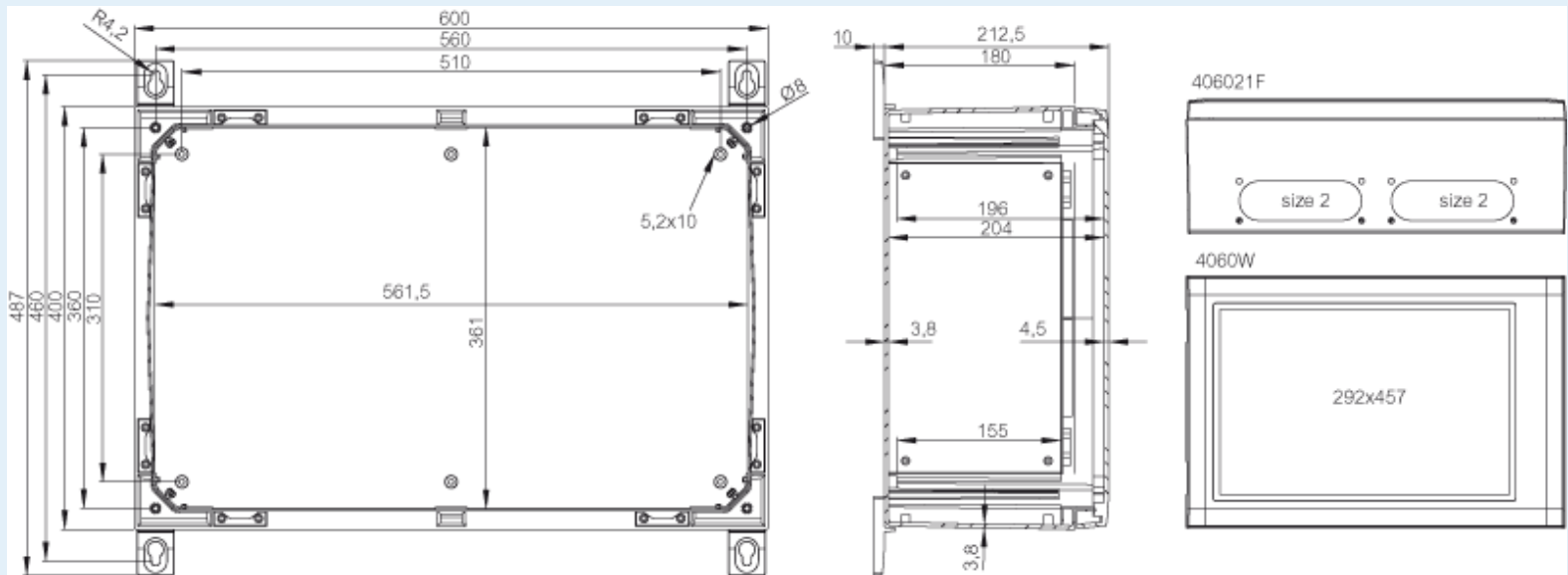

Dimensions :	Height	Width	Depth
mm :	400	600	210
inch :	15.75	23.62	8.27

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035

Accessories :

MPS ARCA 6040	Mounting plate (550x350x2 mm) (550 x 350 x 2)
PMK ARCA 60	PoleMounting kit, for pole ø100-300mm (585 x 385 x 35)
MPP ARCA 4060	Mounting plate perforated (550x350x2 mm - 26x11 mm)
DSP ARCA HRS	Door stopper ARCA, horizontal, right, small
IDS ARCA	Inner door set

Cover colour : RAL 7035 -light grey

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

4060

DSP ARCA
HLS Door stopper ARCA, horizontal, left, small

MPMP ARCA
6040 Mounting plate multiperforated (550x350x2
mm - ø3.6 mm)

DRS ARCA
406021 DIN rail frame set
(585 x 385 x 35)

MPX ARCA
6040 Mounting plate (550x350 mm)
(550 x 350 x 15)

RCS ARCA
4060 Rain canopy set for size 4060

Ratings :

Ingress protection (EN 60529): IP66;

Impact Resistance (EN 62262): IK10;

electrical_insulation : Totally insulated

Halogen free (DIN/VDE 0472, Part
815) : Yes

UV resistance : UL 746C

Flammability Rating : UL 94 5VA

Glow Wire Test (IEC 695-2-1) °C : 960C

UL Type NEMA_1_4_4X_12_13

Certificates :

Certificate FI 40467