

ARCA 505021



Sample image

Order symbol : ARCA 505021

Product nr : 8120032

UL Code : UL508A

Description : Cabinet, PC


Remarks : Grey cover, 2-point locking, hinges on the long side

EAN : 6418074314642

El. number :



- Finland : 3424434
- Denmark : 8212097599

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

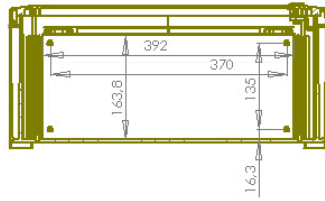

ARCA IEC DRS

ARCA IEC IDS

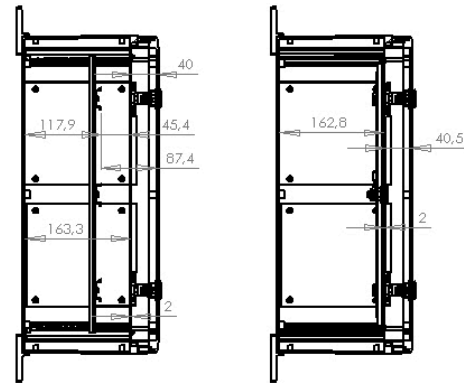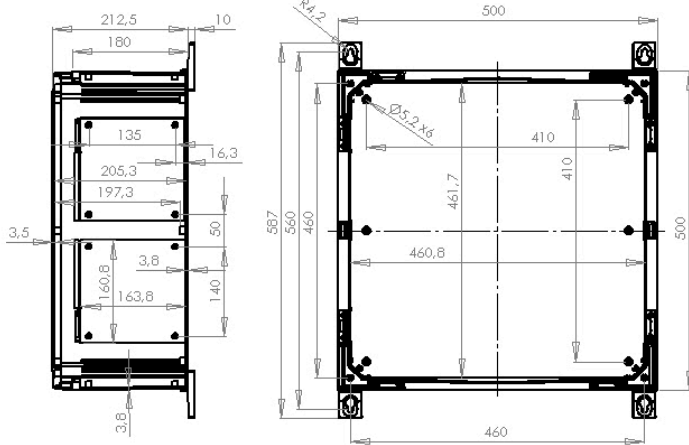

Dimensions :	Height	Width	Depth
mm :	500	500	210
inch :	19.69	19.69	8.27

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

MPMP ARCA 5050	Mounting plate multiperforated (450x450x2 mm - ø3.6 mm) (450 x 450 x 2)
MPX ARCA 5050	Mounting plate (450x450 mm) (450 x 450 x 15)
MPS ARCA 5050	Mounting plate (450x450x2 mm) (450 x 450 x 2)
DRS ARCA 505021	DIN rail frame set (480 x 480 x 30)
RCS ARCA 5050	Rain canopy set for size 5050 (480 x 480 x 30)
IDS ARCA 5050	Inner door set (480 x 480 x 30)
MPP ARCA 5050	Mounting plate perforated (450x450x2 mm - 26x11 mm) (450 x 450 x 2)

Ratings :

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes

UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C
UL Type	NEMA__1_4_4X_12_13