

# ARCA 604021



Sample image

**Order symbol :** ARCA 604021

**Product nr :** 8120012

UL Code : UL508A

**Description :** Cabinet, PC



**Remarks :** Grey cover, 2-point locking, hinges on the long side

**EAN :** 6418074079237

**El. number :**

- Finland : 3423100
- Denmark : 8212091100
- Sweden : 2500118

**Including :** Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

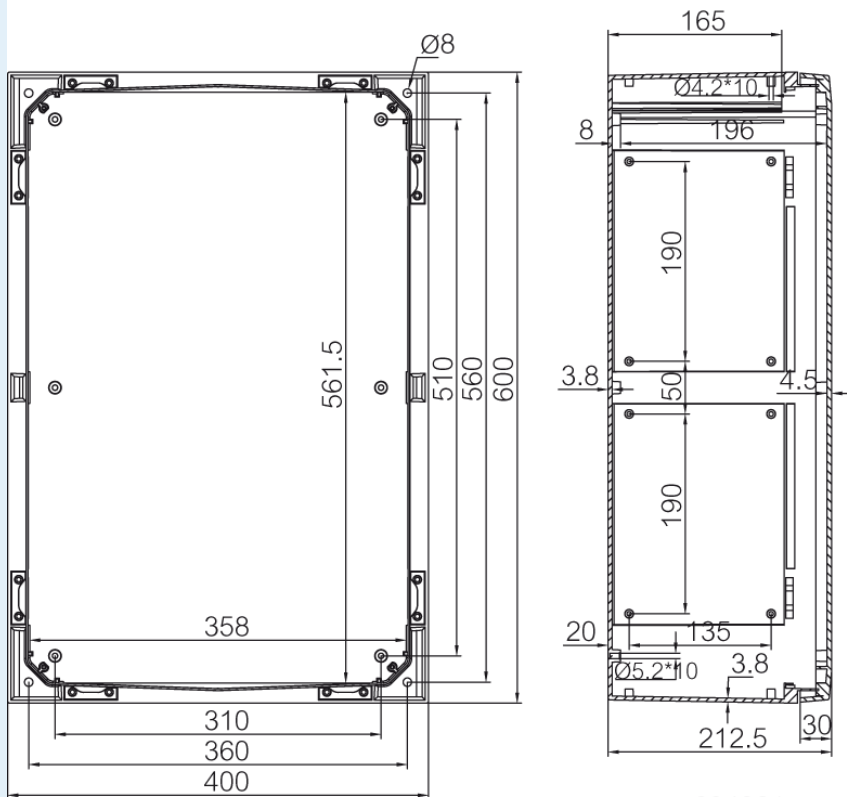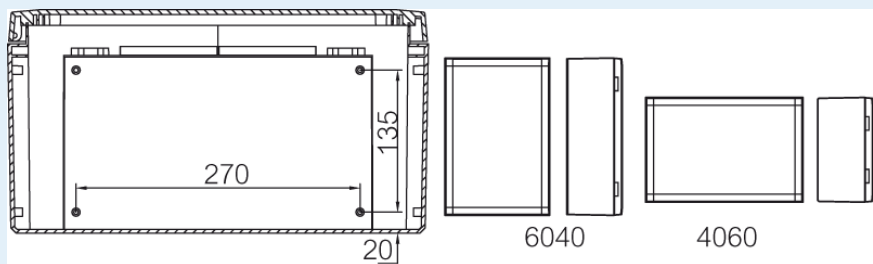

604021

Dimensions :	Height	Width	Depth
mm :	600	400	210
inch :	15.75	23.62	8.58

#### Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

#### Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

#### Accessories :

MPS ARCA 6040	Mounting plate (550x350x2 mm) (550 x 350 x 2)
RCS ARCA 6040	Rain canopy set for size 6040
DRS ARCA 604021	DIN rail frame set (585 x 385 x 35)
PMK ARCA 40	PoleMounting kit, for pole $\varnothing$ 100-300mm (385 x 285 x 35)
MPMP ARCA 6040	Mounting plate multiperforated (550x350x2 mm - $\varnothing$ 3.6 mm)
MPP ARCA 6040	Mounting plate perforated (550x350x2 mm - 26x11 mm)
IDS ARCA 6040	Inner door set (585 x 385 x 35)
MPX ARCA 6040	Mounting plate (550x350 mm) (550 x 350 x 15)
DSP ARCA VLS	Door stopper ARCA, vertical, left, small
DSP ARCA VRS	Door stopper ARCA, vertical, right, small

#### Ratings :

Ingress protection (EN 60529):	IP66;
--------------------------------	-------

Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C
UL Type	NEMA__1_4_4X_12_13

**Certificates :**

Certificate FI 40467