

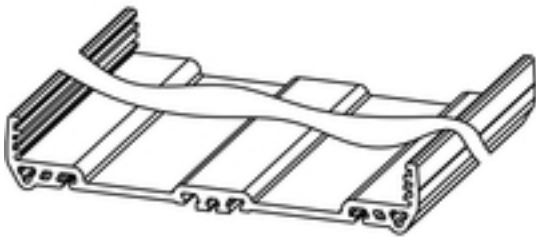
PF RS 122 OR 2000MM**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Flexible - More flexible - Profilform**

Modular housings in profile form - the flexible modular system comprising coloured and transparent plastic profiles and carrier modules

The combination of standard pitches mounted side by side in any arrangement and metre goods cut accurate to the millimetre creates the perfect balance between flexibility and economic efficiency:

- Pitch profiles with standard widths ranging from 5mm to 45mm allow the mounting of all standard PCB formats.
- Variable heights ensure maximum component density, even with larger electronics components.
- The different installation variations mean that mounting the enclosure directly is as easy as clipping components onto the terminal rail
- Solid hoods protect the module reliably from external influences

The recipe for success: variable profile + modular form components = flexible enclosure concept that offers a large surface area for the PCBs.

The modular concept is designed for modules with high space requirements and suitable for small component quantities and different widths.

General ordering data

Version	Mounting rail housing orange, Extruded profile, Width: 2000 mm
Order No.	1155940000
Type	PF RS 122 OR 2000MM
GTIN (EAN)	4032248942572
Qty.	2 m

PF RS 122 OR 2000MM

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	127 mm	Height (inches)	5 inch
Width	2,000 mm	Width (inches)	78.74 inch
Net weight	750 g		

Material data

Insulating material	PVC	UL 94 flammability rating	V-0
---------------------	-----	---------------------------	-----

General data

Colour	orange	Colour chart (similar)	RAL 2000
Encapsulation option	No	Protection degree	IP00

Classifications

ETIM 6.0	EC002779	ETIM 7.0	EC002779
ETIM 8.0	EC002779	ETIM 9.0	EC002779
ECLASS 9.0	27-18-27-90	ECLASS 9.1	27-18-27-90
ECLASS 10.0	27-18-27-92	ECLASS 11.0	27-18-27-92
ECLASS 12.0	27-18-27-92	ECLASS 13.0	27182792

Important note

Product information	<p>2 optional positions for the PCB</p> <p>Dimensions of the PCB:</p> <p>Thickness: 1.6 (±0.2) mm, width: 122 (+0.5) mm</p> <p>Dimension of RS section = PCB length - 5 mm</p> <p>Example:</p> <p>PCB length 160 mm, RS section = 155 mm</p>
---------------------	--

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	FL ANALO.SIGN.CONV.EN
	MB DEVICE MANUF.EN
	FL MACHINE SAFETY EN
	FL 72H SAMPLE SER EN
	PO OMNIMATE EN
	PO OMNIMATE EN

Data sheet

PF RS 122 OR 2000MM

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

