

AB 080806



Sample image

Order symbol : AB 080806

Product nr : 7083540

Description : Enclosure, ABS


Remarks : Grey cover

EAN : 6418074058737

El. number :

- Finland : 3435458
- Denmark : 8212003253
- Sweden : 7083540

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

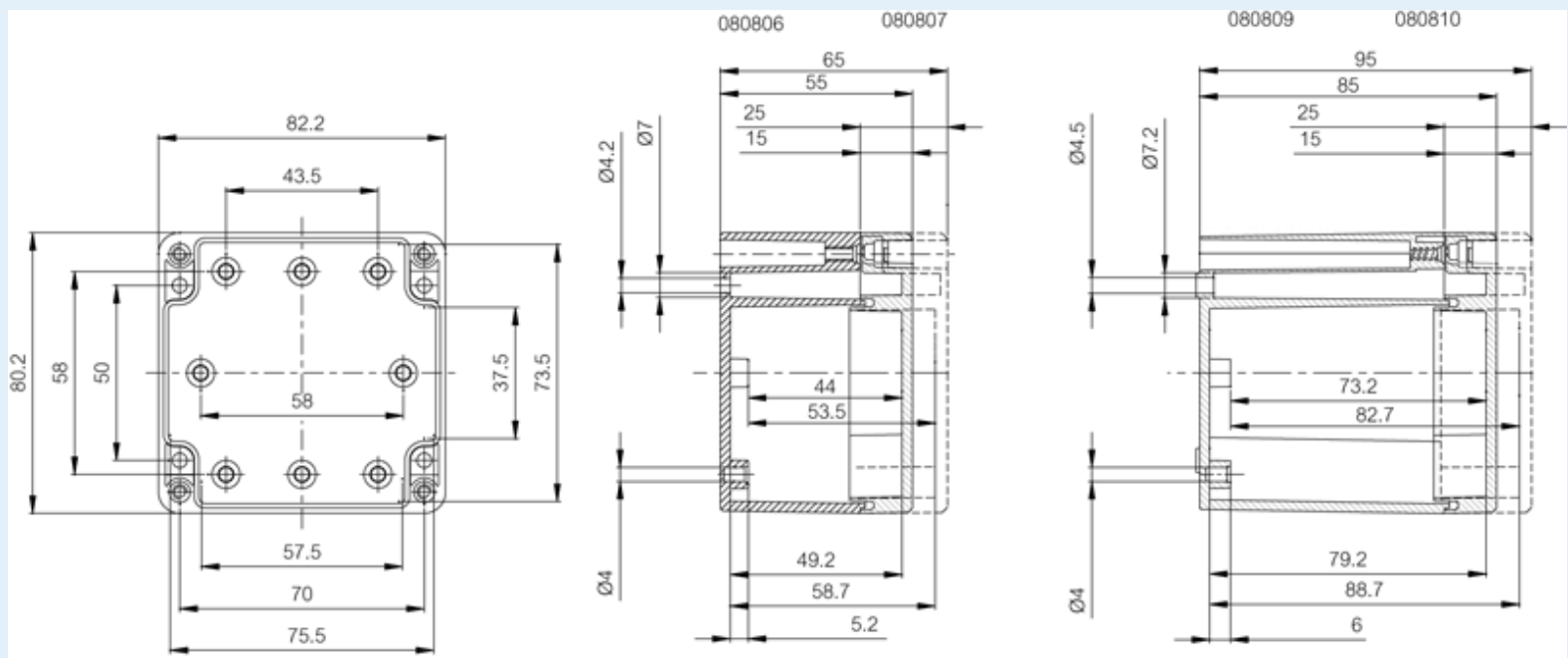

Dimensions :	Height	Width	Depth
mm :	80	82	55
inch :	3.15	3.23	2.17

Materials :

Material :	ABS
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey

Accessories :

TF 28037	Wall fastening lug (4 pcs), for enclosures:
TM 0808	Mounting plate, for enclosures: (56 x 71 x 1)
TH A	Grey plastic hinges (2 pcs)
TRM 0808	DIN-15 Mounting rail, for enclosures: (68 x 15 x 1)

Ratings :

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 60

Temperature °F (continuous) : -40 ... 140

Ingress protection (EN 60529): IP66; IP67;
Impact Resistance (EN 62262): IK07;
electrical_insulation : Totally insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : -
Flammability Rating : UL 94 HB
Glow Wire Test (IEC 695-2-1) °C : 650C

Certificates :

SGSFimko_EURONORD