

# AB 122009



Sample image

**Order symbol :** AB 122009

**Product nr :** 7083770

**Description :** Enclosure, ABS


**Remarks :** Grey cover

**EAN :** 6418074058843

**El. number :**

- Finland : 3435480
- Denmark : 8212003538
- Sweden : 7083770

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

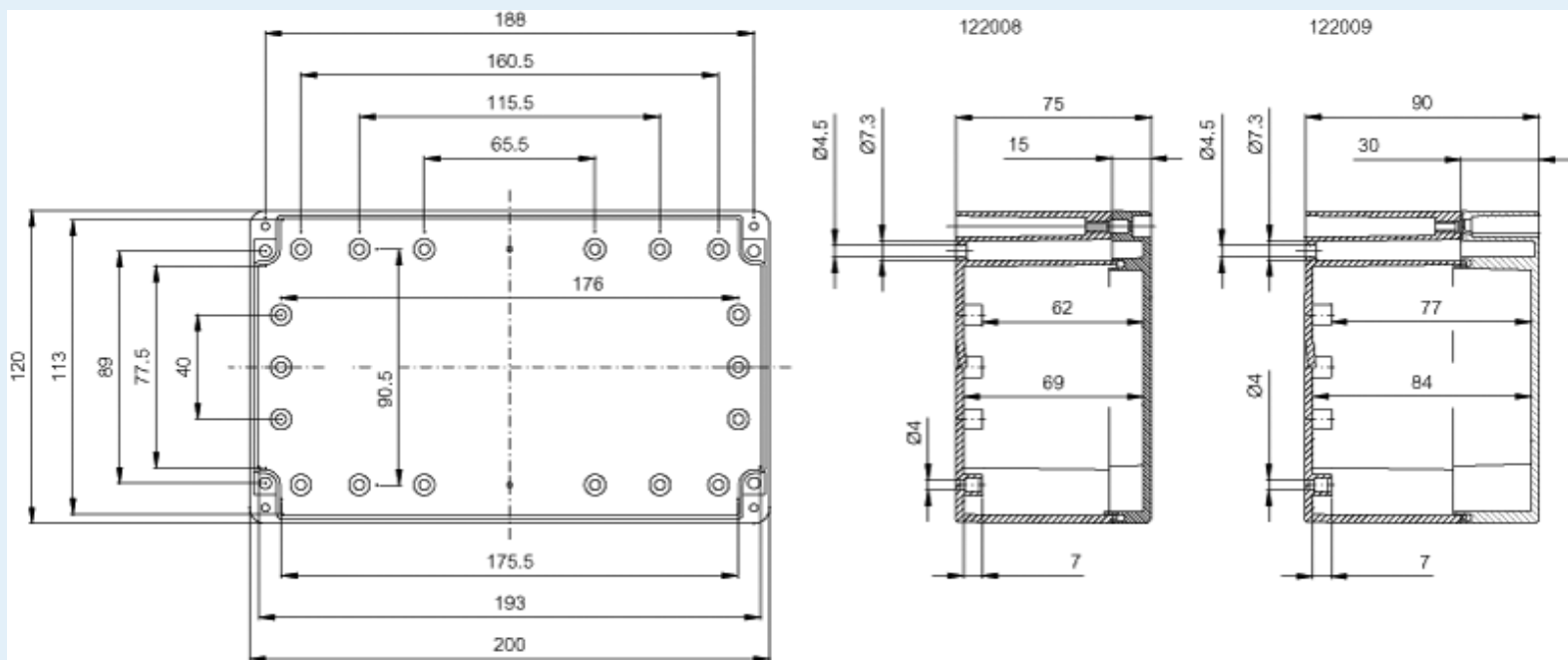

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 120    | 200   | 90    |
| inch :       | 4.72   | 7.87  | 3.54  |

## Materials :

|                |                      |
|----------------|----------------------|
| Material :     | ABS                  |
| Base colour :  | RAL_7035             |
| Cover colour : | RAL 7035 -light grey |

## Accessories :

|          |                                                         |
|----------|---------------------------------------------------------|
| MIV 10   | DIN-35 Mounting rail, for enclosures:<br>(100 x 35 x 1) |
| TF 28037 | Wall fastening lug (4 pcs), for enclosures:             |
| TRH 1220 | DIN-35 Mounting rail, for enclosures:<br>(186 x 35 x 1) |
| TM 1220  | Mounting plate, for enclosures:<br>(111 x 174 x 2)      |
| TH A     | Grey plastic hinges (2 pcs)                             |

|                               |              |
|-------------------------------|--------------|
| Gasket material :             | Polyurethane |
| <b>Temperatures :</b>         |              |
| Temperature °C (continuous) : | -40 ... 60   |
| Temperature °F (continuous) : | -40 ... 140  |

|                                         |                   |
|-----------------------------------------|-------------------|
| <b>Ratings :</b>                        |                   |
| Ingress protection (EN 60529):          | IP66; IP67;       |
| Impact Resistance (EN 62262):           | IK07;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | -                 |
| Flammability Rating :                   | UL 94 HB          |
| Glow Wire Test (IEC 695-2-1) °C :       | 650C              |

|                       |  |
|-----------------------|--|
| <b>Certificates :</b> |  |
| SGSFimko_EURONORD     |  |