

ALN 060605



Order symbol : ALN 060605

Product nr : 7811060

UL Name : ALN UL 060605

Description : Enclosure, aluminium

Remarks : Aluminium


EAN : 6418074016034

El. number :

- Finland : 3413045
- Denmark : 8212045619
- Sweden : 2500901

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

Sample image

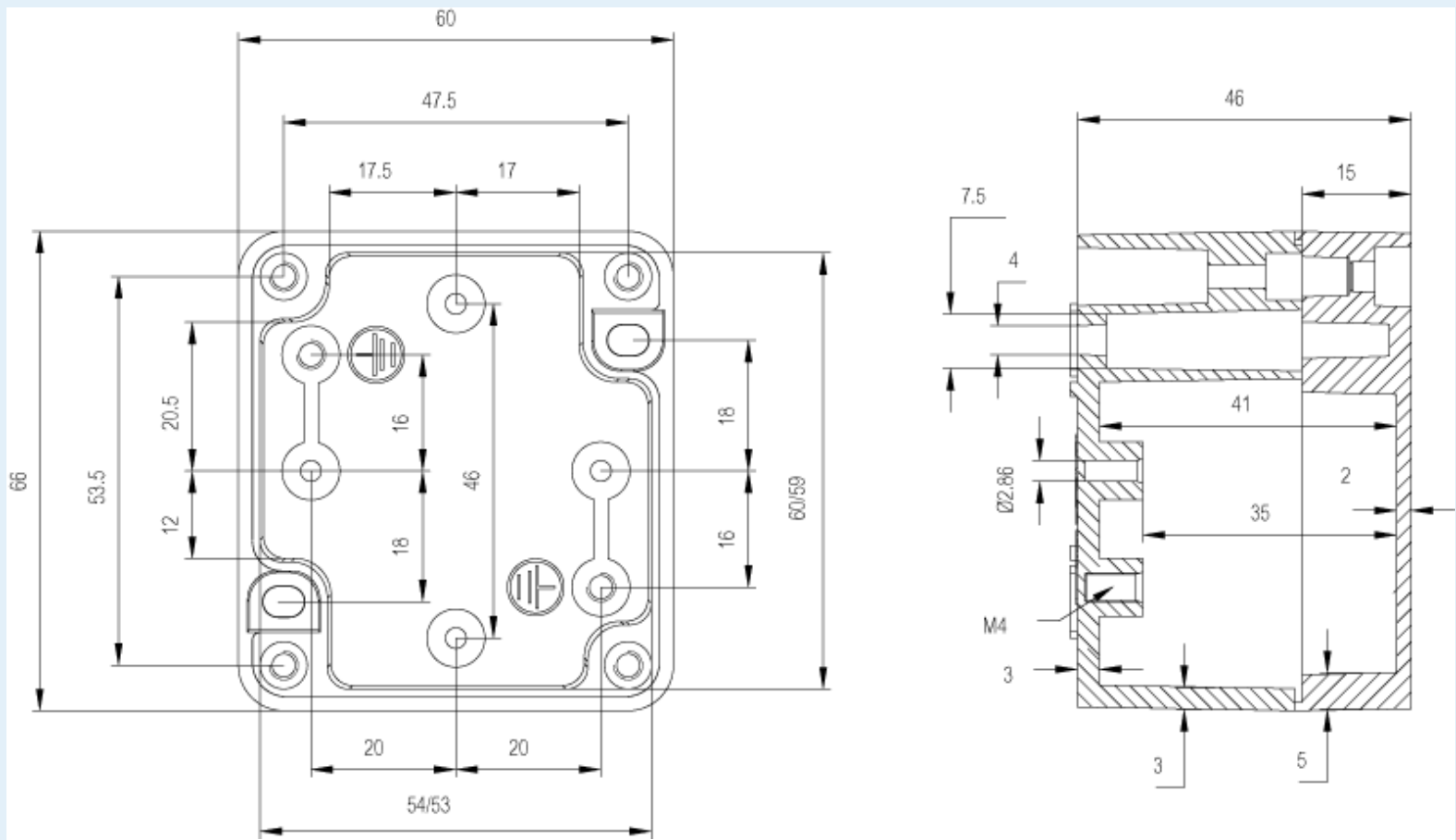

Dimensions :	Height	Width	Depth
mm :	66	60	46
inch :	2.6	2.36	1.81

Accessories :

MIV 5 DIN-35 Mounting rail, for enclosures:
(50 x 35 x 1)

Materials :

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

MR 75003	Selftapping taptite screw M3, for enclosures:
TRM 0507	DIN-15 Mounting rail, for enclosures: (48 x 15 x 1)
MRS 28540	Wall fastening lug (2 pcs), for enclosures: (11 x 42 x 1)

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU