

ALN 061005



Sample image

Order symbol : ALN 061005

Product nr : 7811080

UL Name : ALN UL 061005

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016041

El. number :

- Finland : 3420042
- Denmark : 8212045622
- Sweden : 2500902

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

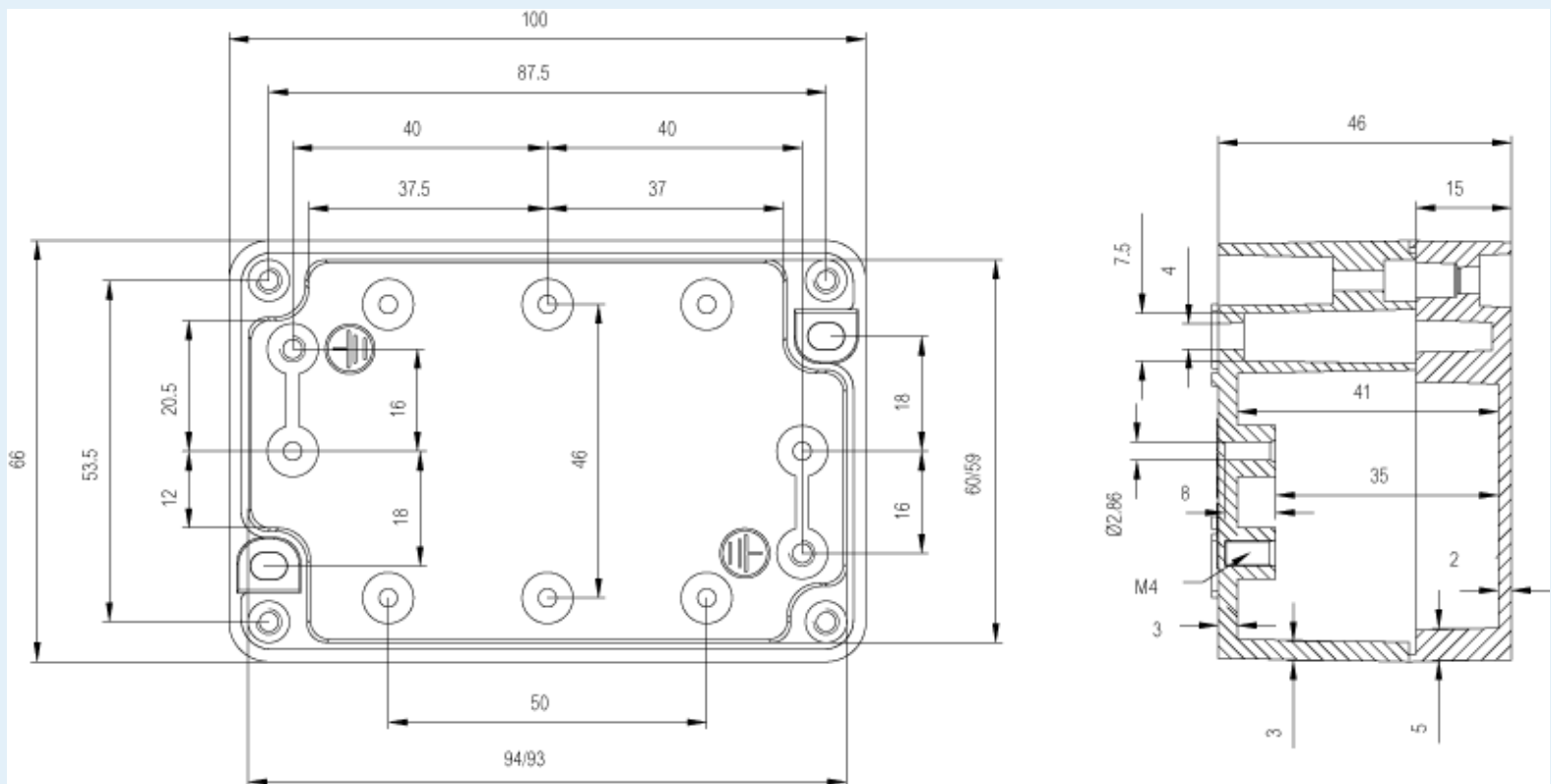

Dimensions :

	Height	Width	Depth
--	--------	-------	-------

mm :	66	100	46
inch :	2.6	3.94	1.81

Materials :

Accessories :

ARM 0610	DIN-15 Mounting rail, for enclosures: (88 x 15 x 1)
MR 75003	Selftapping taptite screw M3, for enclosures:
MRS 28540	Wall fastening lug (2 pcs), for enclosures: (11 x 42 x 1)

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU