

ALN 080806



Sample image

Order symbol : ALN 080806

Product nr : 7811130

UL Name : ALN UL 080806

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016065

El. number :

- Finland : 3420044
- Denmark : 8212045648
- Sweden : 2500906

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

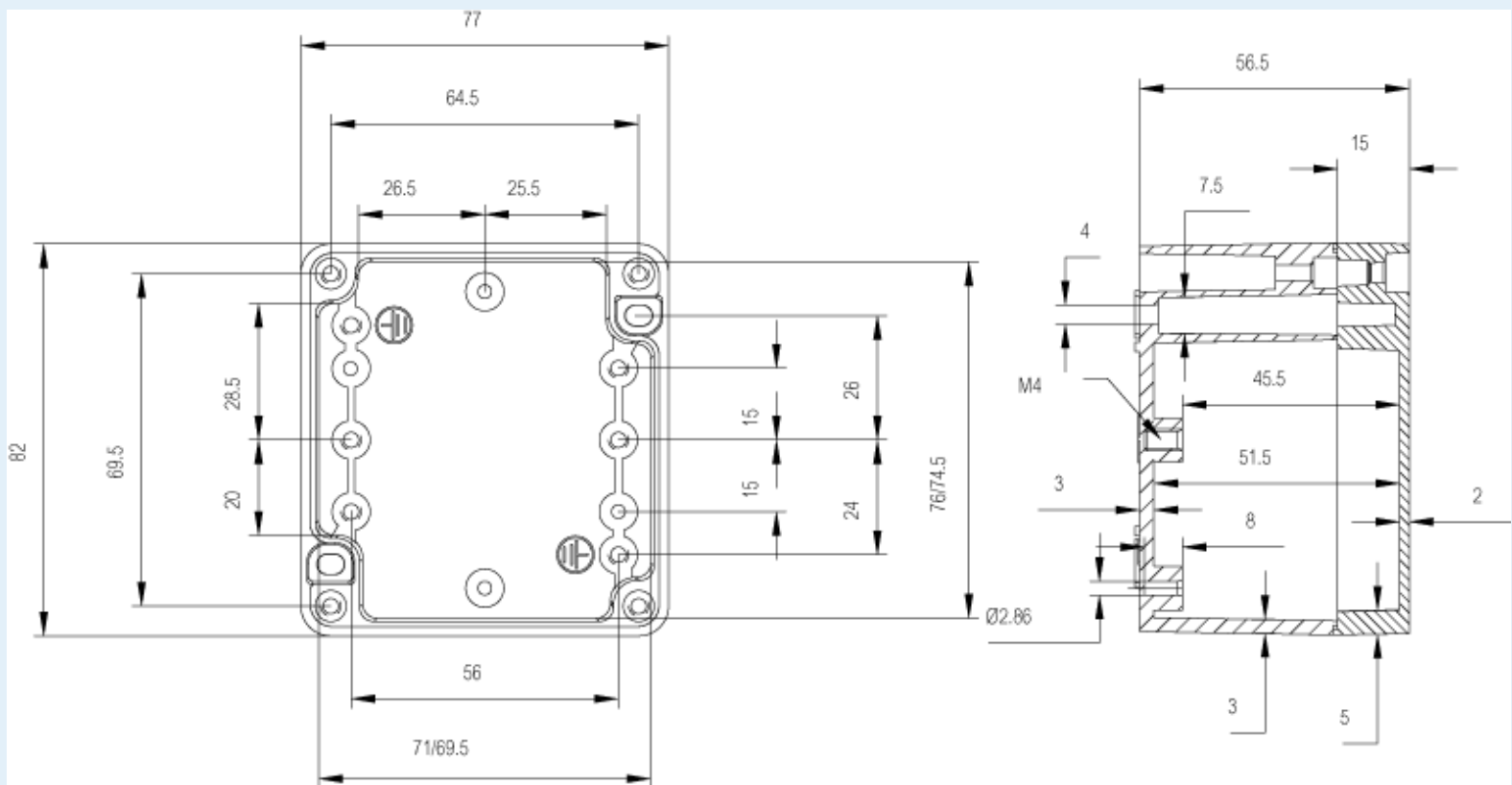

Dimensions :	Height	Width	Depth
mm :	82	77	57
inch :	3.23	3.03	2.24

Accessories :

AM 0808	Mounting plate, for enclosures: (69 x 64 x 1)
MR 75003	Selftapping taptite screw M3, for enclosures:
MRS 28540	Wall fastening lug (2 pcs), for enclosures: (11 x 42 x 1)

Materials :

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

ARM 0808 DIN-15 Mounting rail, for enclosures:
(65 x 15 x 1)

TRM 0808 DIN-15 Mounting rail, for enclosures:
(68 x 15 x 1)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU