

ALN 081806



Sample image

Order symbol : ALN 081806

Product nr : 7811170

UL Name : ALN UL 081806

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016089

El. number :

- Finland : 3420046
- Denmark : 8212045664
- Sweden : 2500910

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

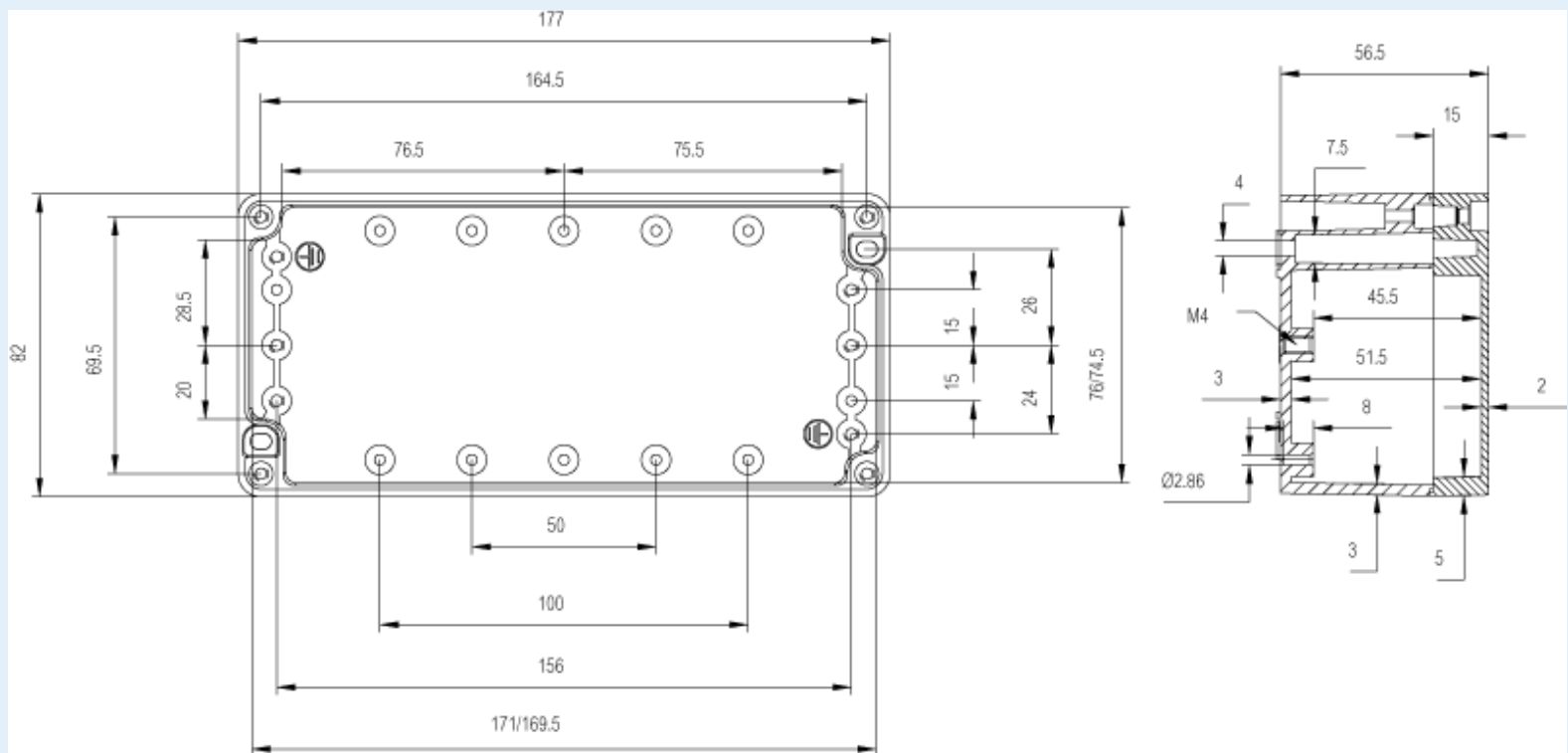

Dimensions :

	Height	Width	Depth
mm :	81	177	57
inch :	3.19	6.97	2.24

Materials :

Material : Aluminum

Accessories :

EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)
AM 0818	Mounting plate, for enclosures: (69 x 164 x 1)
MR 75003	Selftapping taptite screw M3, for enclosures:
MRS 28540	Wall fastening lug (2 pcs), for enclosures:

Base colour : RAL_7001
Cover colour : RAL 7001
Gasket material : Polyurethane

(11 x 42 x 1)
ARM 0818 DIN-15 Mounting rail, for enclosures:
(165 x 15 x 1)

Temperatures :

Temperature °C (continuous) : -50 ... 80
Temperature °F (continuous) : -60 ... 175

Ratings :

Ingress protection (EN 60529): IP66; IP67; IP68;
Impact Resistance (EN 62262): IK08;
electrical_insulation : Not insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : UL 746C
UL Type NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU