

# ALN 122208



Sample image

**Order symbol :** ALN 122208

**Product nr :** 7811230

UL Name : ALN UL 122208

**Description :** Enclosure, aluminium

**Remarks :** Aluminium


**EAN :** 6418074016119

**El. number :**

- Finland : 3420049
- Denmark : 8212045693
- Sweden : 2500913

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

ALU 222x125x81

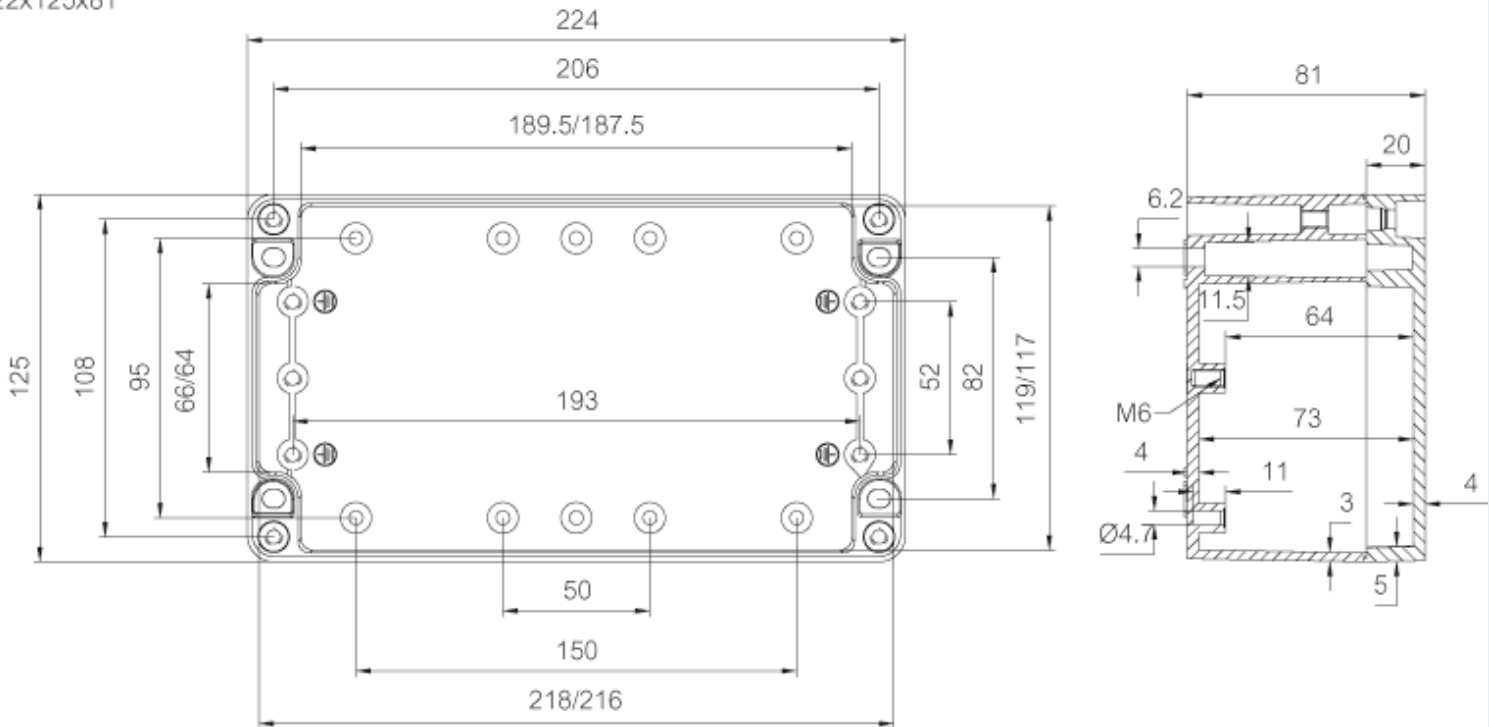

Dimensions :	Height	Width	Depth
mm :	125	222	81
inch :	4.92	8.74	3.19

**Materials :**

Material : Aluminum

**Accessories :**

- ARH 22 DIN-35 Mounting rail, for enclosures: (203 x 35 x 1)
- MR 75005 Selftapping taptite screw M5, for enclosures:
- MRS 28541 Wall fastening lug (2 pcs), for enclosures: (15 x 50 x 1)
- AM 1222 Mounting plate, for enclosures: (107 x 207 x 1)

Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

**Temperatures :**

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

**Certificates :**

SGSFIMKO\_ALU