

ALN 162609



Sample image

Order symbol : ALN 162609

Product nr : 7811290

UL Name : ALN UL 162609

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016133

El. number :

- Finland : 3420052
- Denmark : 8212045729
- Sweden : 2500918

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

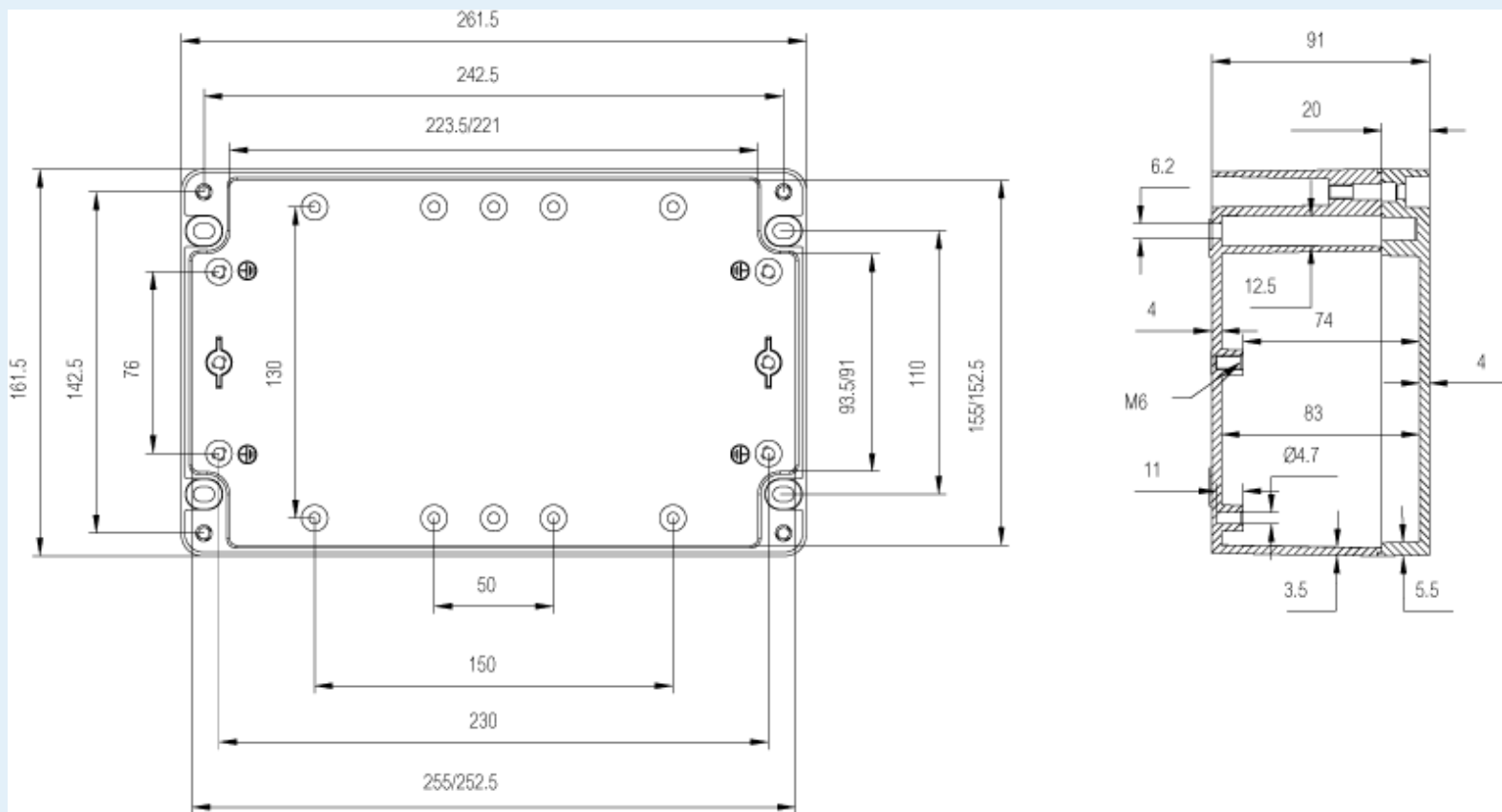

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm : | 162 | 263 | 91 |
| inch : | 6.38 | 10.35 | 3.58 |

Accessories :

- AM 1626 Mounting plate, for enclosures: (146 x 244 x 1)
- ARH 26 DIN-35 Mounting rail, for enclosures: (240 x 35 x 1)

Materials :

| | |
|-------------------|--------------|
| Material : | Aluminum |
| Base colour : | RAL_7001 |
| Cover colour : | RAL 7001 |
| Gasket material : | Polyurethane |

| | |
|-----------|--|
| MR 75005 | Selftapping taptite screw M5, for enclosures: |
| MRS 28541 | Wall fastening lug (2 pcs), for enclosures: (15 x 50 x 1) |
| ARM 0825 | DIN-15 Mounting rail, for enclosures: (240 x 15 x 1) |

Temperatures :

| | |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -50 ... 80 |
| Temperature °F (continuous) : | -60 ... 175 |

Ratings :

| | |
|---|----------------------|
| Ingress protection (EN 60529): | IP66; IP67; IP68; |
| Impact Resistance (EN 62262): | IK08; |
| electrical_insulation : | Not insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes |
| UV resistance : | UL 746C |
| UL Type | NEMA__1_4_4X_6_12_13 |

Certificates :

SGSFIMKO_ALU