

ALN 232811



Sample image

Order symbol : ALN 232811

Product nr : 7811370

UL Name : ALN UL 232811

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016188

El. number :

- Finland : 3420037
- Denmark : 8212054011
- Sweden : 2500922

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

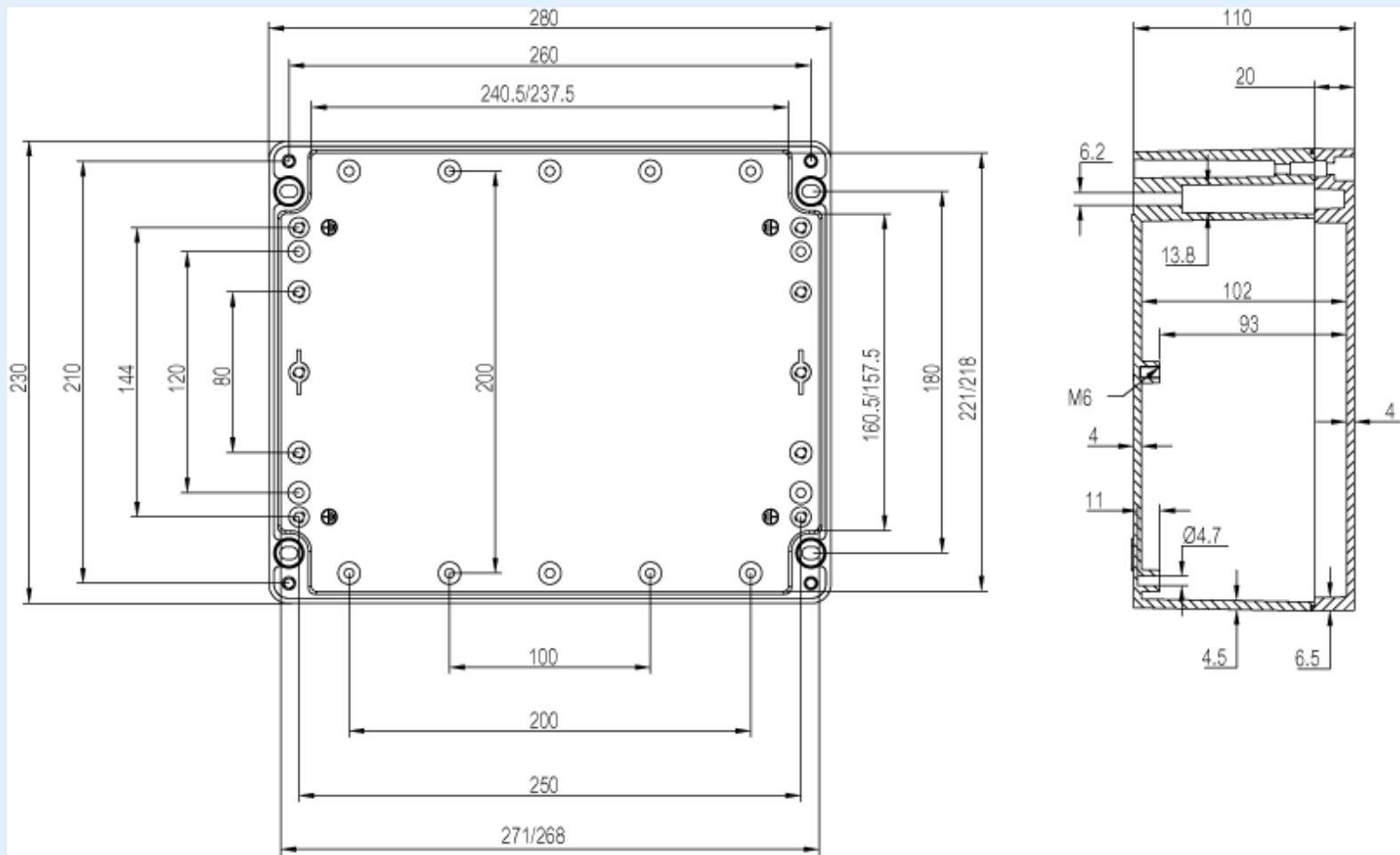

Dimensions :

Height

Width

Depth

Ratings :

mm :	230	280	110
inch :	9.06	11.02	4.33

Materials :

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU