

ALN 233311



Sample image

Order symbol : ALN 233311

Product nr : 7811380

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016195

El. number :

- Finland : 3420038
- Denmark : 8212045757
- Sweden : 2500923

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

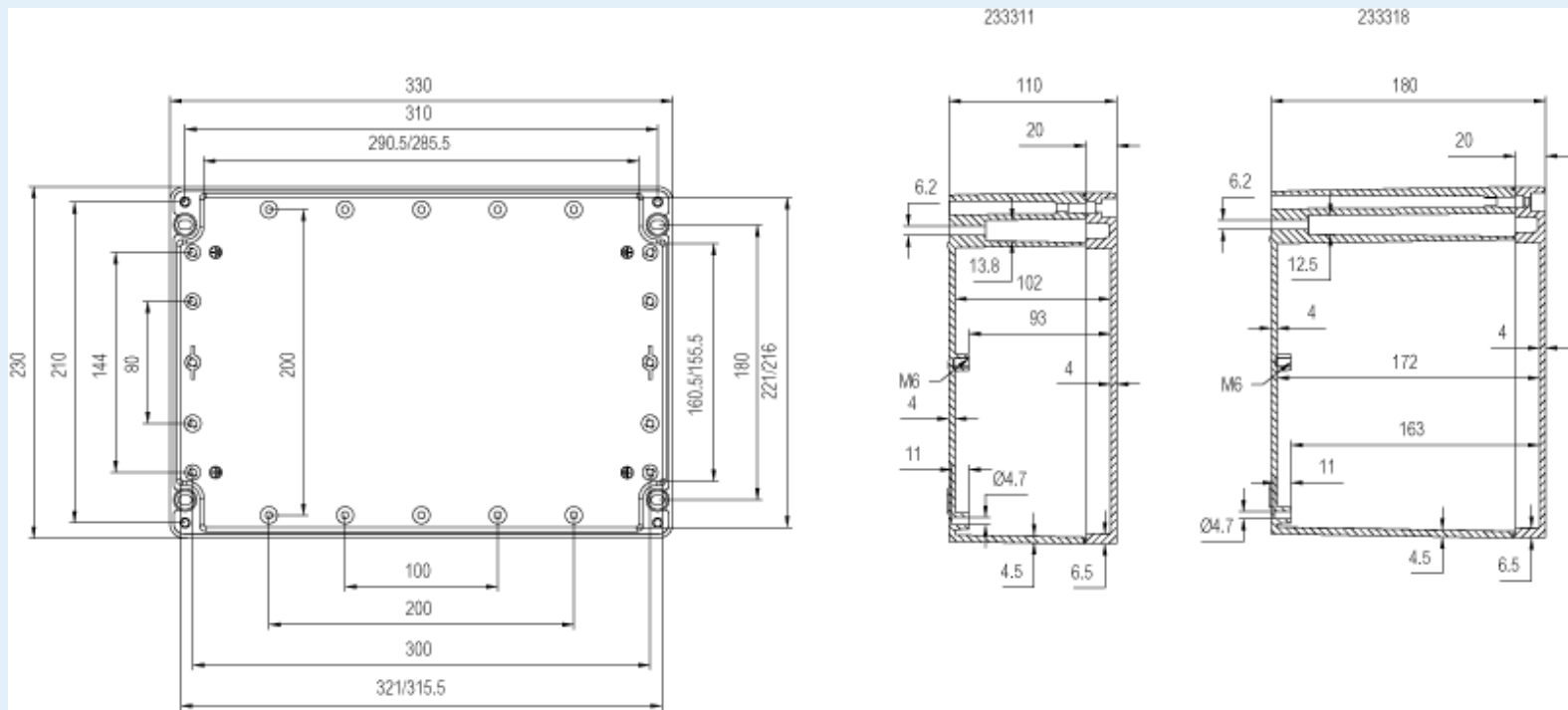

Dimensions :	Height	Width	Depth
mm :	230	330	110
inch :	9.06	12.99	4.33

Materials :

Material :	Aluminum
Base colour :	RAL_7001

Ratings :

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Cover colour : RAL 7001
Gasket material : Polyurethane

Certificates :
SGSFIMKO_ALU

Temperatures :

Temperature °C (continuous) : -50 ... 80
Temperature °F (continuous) : -60 ... 175