

ALN 234018



Sample image

Order symbol : ALN 234018

EAN : 6418074016225

Product nr : 7811410


El. number :

Description : Enclosure, aluminium

- Finland : 3420002
- Denmark : 8212045813
- Sweden : 2500926

Remarks : Aluminium

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

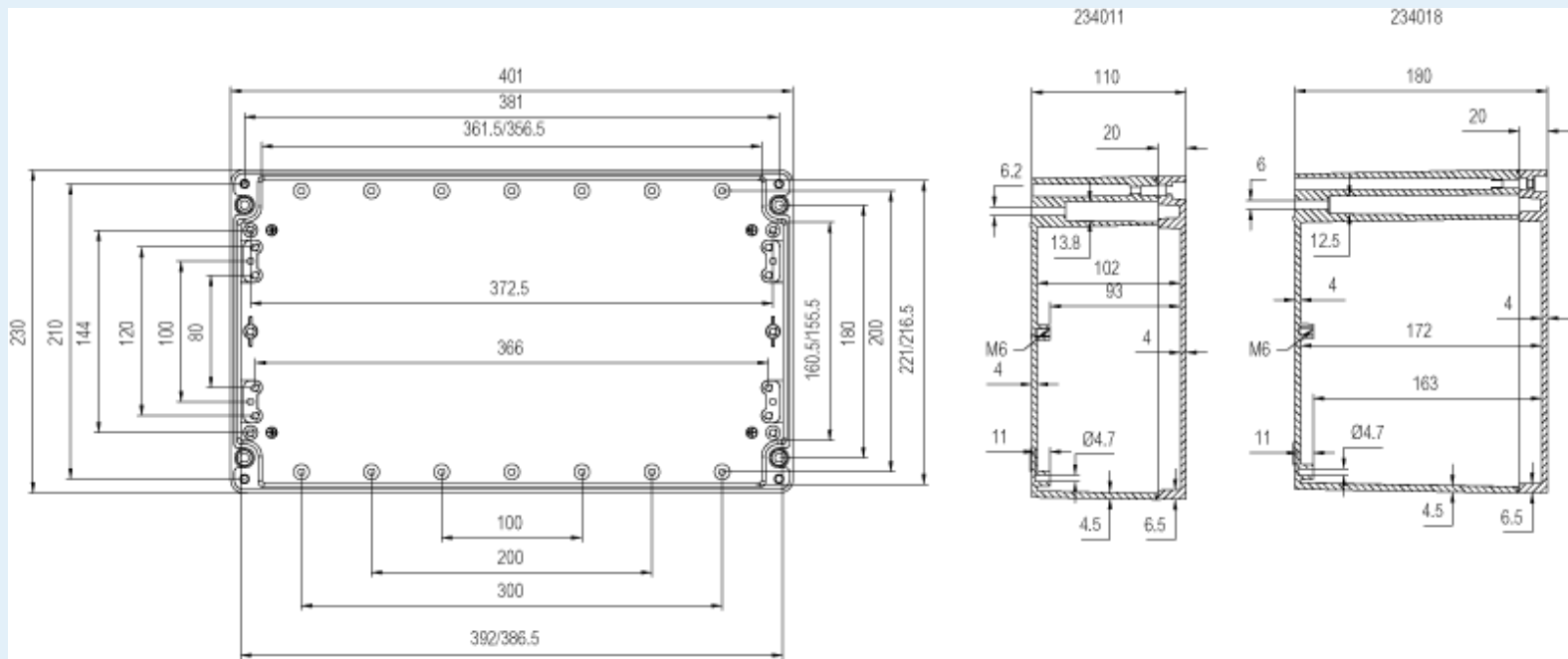

Dimensions :	Height	Width	Depth
mm :	230	401	180
inch :	9.06	15.79	7.09

Materials :

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001

Accessories :

ARH 40	DIN-35 Mounting rail, for enclosures: (383 x 35 x 1)
AM 2340	Mounting plate, for enclosures: (215 x 385 x 2)
MRS 28541	Wall fastening lug (2 pcs), for enclosures: (15 x 50 x 1)

Ratings :

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -50 ... 80

Temperature °F (continuous) : -60 ... 175

Ingress protection (EN 60529): IP66; IP67; IP68;

Impact Resistance (EN 62262): IK08;

electrical_insulation : Not insulated

Halogen free (DIN/VDE 0472, Part 815) : Yes

UV resistance : UL 746C

UL Type NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU