

ALN 314018



Sample image

Order symbol : ALN 314018

Product nr : 7811460

Description : Enclosure, aluminium


Remarks : Aluminium

EAN : 6418074016256

El. number :

- Finland : 3420006
- Denmark : 8212045842
- Sweden : 2500928

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

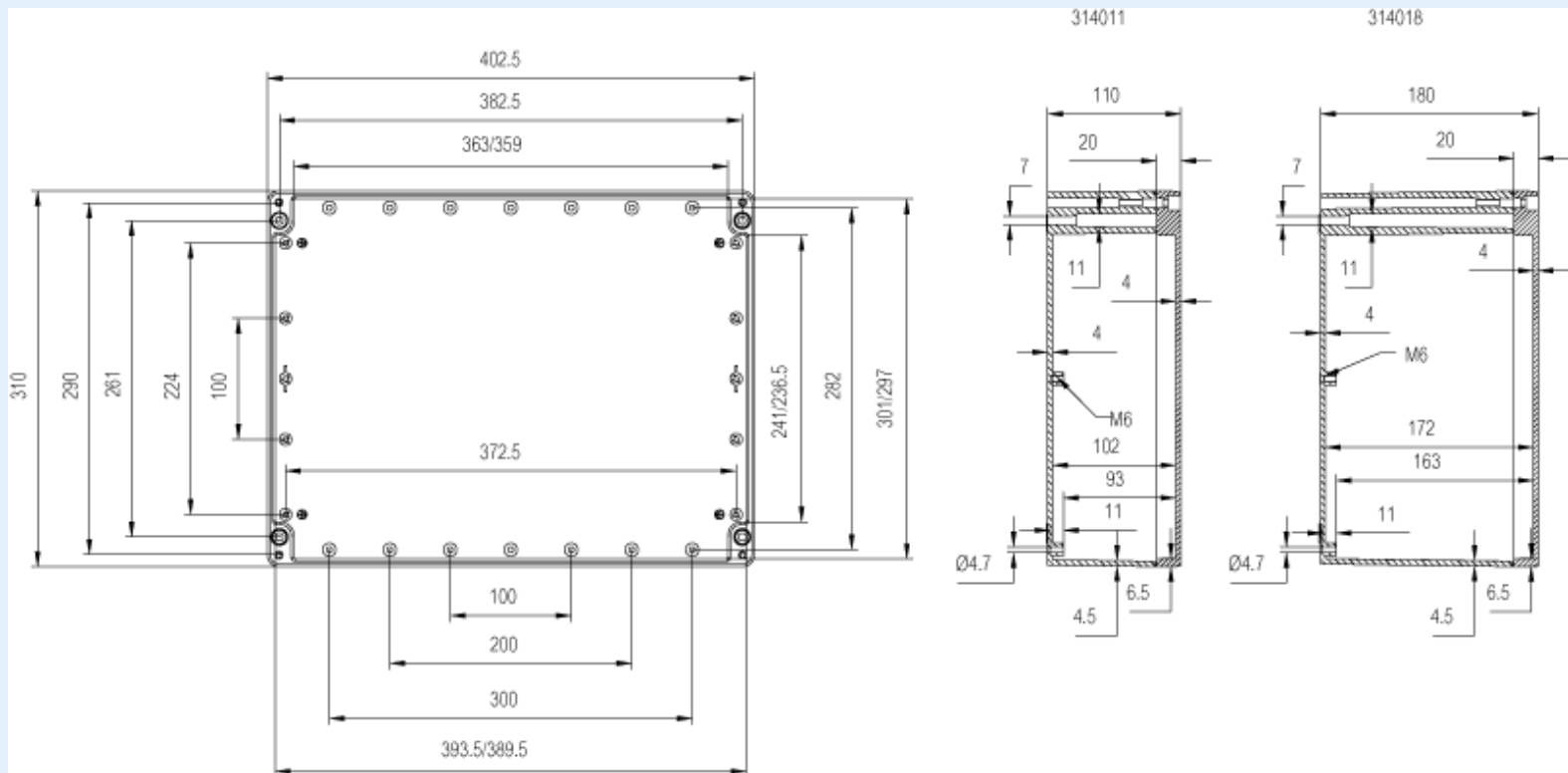

Dimensions :

	Height	Width	Depth
mm :	310	403	180
inch :	12.2	15.87	7.09

Materials :

Accessories :

- ARH 40 DIN-35 Mounting rail, for enclosures: (383 x 35 x 1)
- AM 3140 Mounting plate, for enclosures: (294 x 387 x 1)
- MRS 28541 Wall fastening lug (2 pcs), for enclosures: (15 x 50 x 1)

Material :	Aluminum
Base colour :	RAL_7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU