

ALN 316011



Sample image

Order symbol : ALN 316011

EAN : 6418074010834

Product nr : 7811470


El. number :

Description : Enclosure, aluminium

- Finland : 3420007
- Denmark : 8212054024
- Sweden : 2500930

Remarks : Aluminium

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

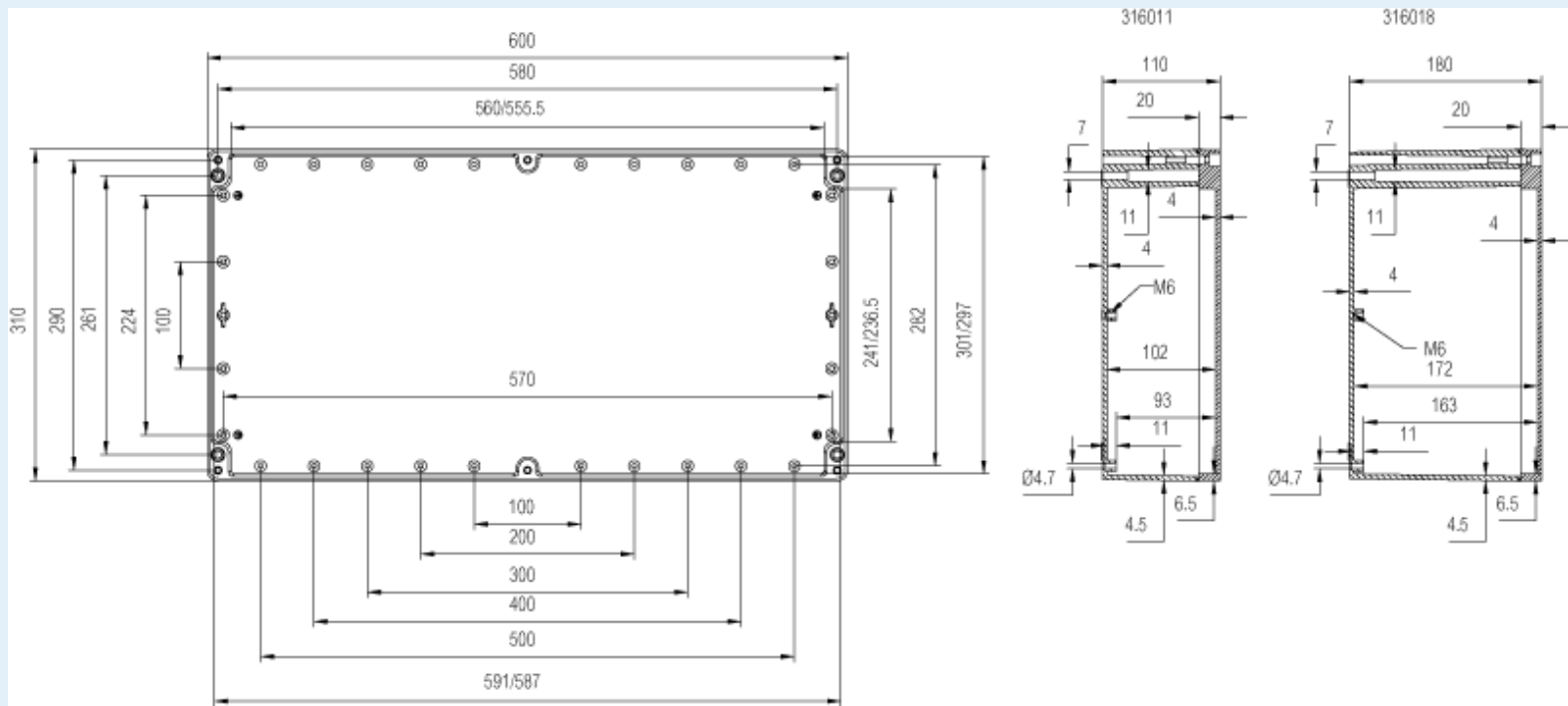

Dimensions :	Height	Width	Depth
mm :	310	600	110
inch :	12.2	23.62	4.33

Materials :

Material : Aluminum
Base colour : RAL_7001

Accessories :

- AM 3160 Mounting plate, for enclosures: (293 x 585 x 1)
- ARH 60 DIN-35 Mounting rail, for enclosures: (580 x 35 x 1)
- MRS 28541 Wall fastening lug (2 pcs), for enclosures: (15 x 50 x 1)

Cover colour :	RAL 7001
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-50 ... 80
Temperature °F (continuous) :	-60 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
UL Type	NEMA__1_4_4X_6_12_13

Certificates :

SGSFIMKO_ALU