

ARCA 507030S



Sample image

Order symbol : ARCA 507030S

Product nr : 8120111

UL Code : UL508A

Description : Cabinet, PC


Remarks : Grey cover, Swinghandle, hinges on the short side

EAN : 6418074086044

El. number :

- Finland : 3424066
- Denmark : 8212095423

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

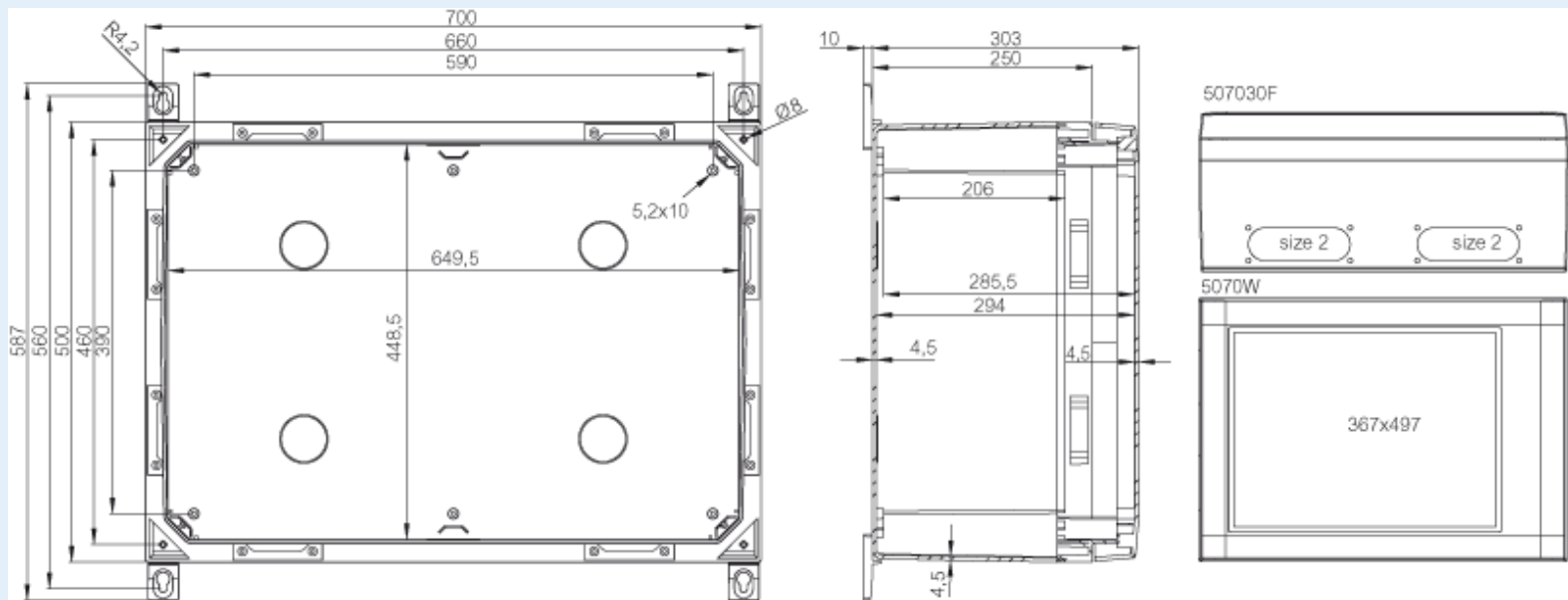

Dimensions :	Height	Width	Depth
mm :	500	700	300
inch :	27.56	19.69	12.2

Materials :

Material : Polycarbonate
Base colour : RAL_7035

Accessories :

- MPX ARCA 7050 Mounting plate (630x430 mm) (630 x 430 x 15)
- PMK ARCA 70 PoleMounting kit, for pole \varnothing 100-300mm (685 x 485 x 35)
- RCS ARCA 5070 Rain canopy set for size 5070
- DSP ARCA RM Door stopper ARCA, right, midsize 5070-8060
- DRS ARCA 507030 DIN rail frame set (685 x 485 x 35)

Cover colour : RAL 7035 -light grey
Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80
Temperature °F (continuous) : -40 ... 175

IDS ARCA 5070 Inner door set
DSP ARCA LM Door stopper ARCA, left, midsize 5070-8060
MPS ARCA 7050 Mounting plate (630x430x2 mm)
(630 x 430 x 2)
MPMP ARCA 7050 Mounting plate multiperforated (630x430x2 mm - ø3.6 mm)
MPP ARCA 5070 Mounting plate perforated (630x430x2 mm - 26x11 mm)

Ratings :

Ingress protection (EN 60529): IP66;
Impact Resistance (EN 62262): IK10;
electrical_insulation : Totally insulated
Halogen free (DIN/VDE 0472, Part 815) : Yes
UV resistance : UL 746C
Flammability Rating : UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

Certificate FI 40467