

# ARCA 705030S



Sample image

**Order symbol :** ARCA 705030S

**Product nr :** 8120097

UL Code : UL508A

**Description :** Cabinet, PC


**Remarks :** Grey cover, Swinghandle, hinges on the long side

**EAN :** 6418074079800

**El. number :**

- Finland : 3423176
- Denmark : 8212091676

**Including :** Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

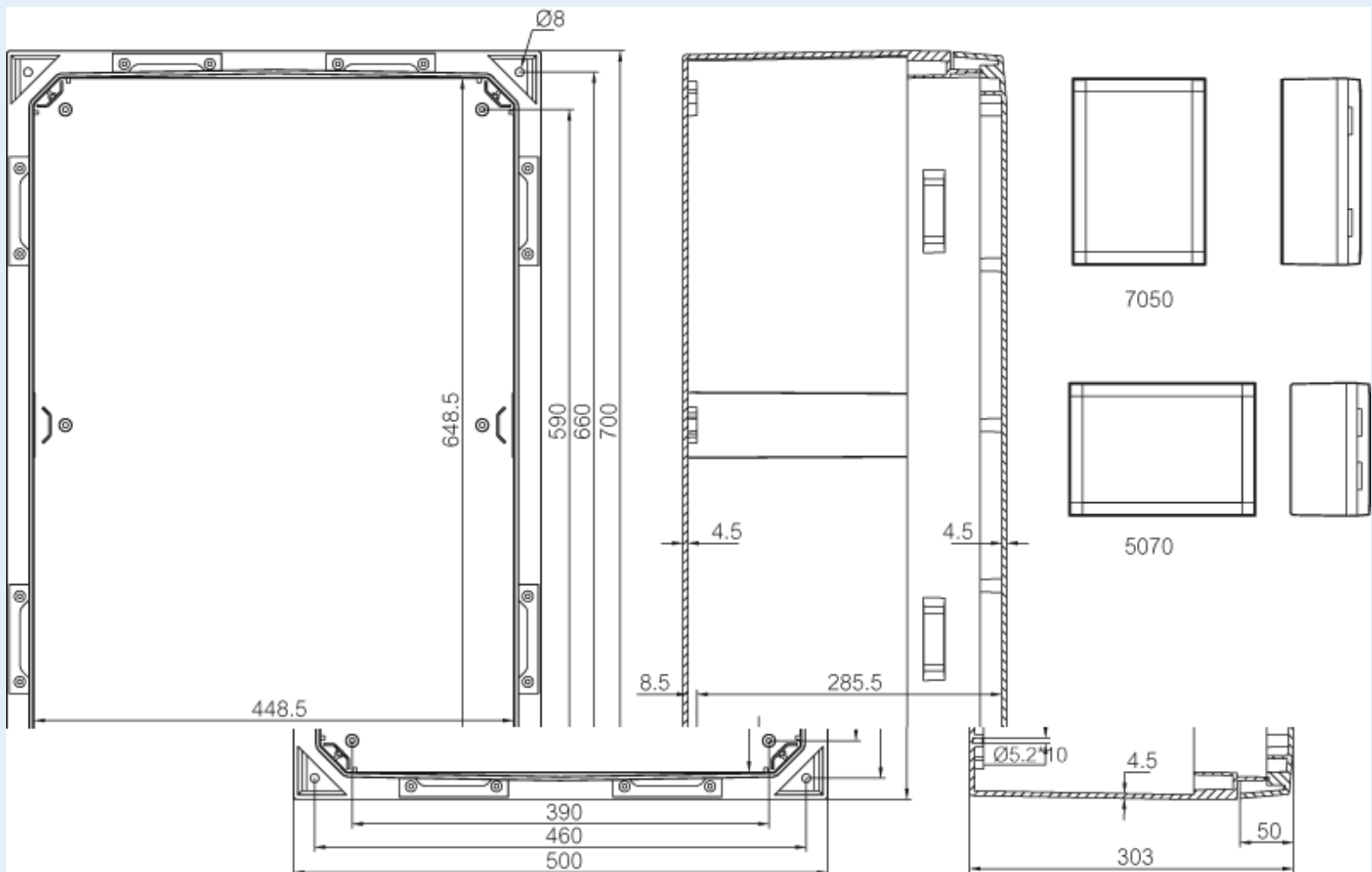

<b>Dimensions :</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	700	500	300
inch :	19.69	27.56	12.2

#### **Materials :**

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

#### **Temperatures :**

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

#### **Accessories :**

MPX ARCA 7050	Mounting plate (630x430 mm) (630 x 430 x 15)
IDS ARCA 7050	Inner door set (685 x 485 x 35)
DSP ARCA RM	Door stopper ARCA, right, midsize 5070-8060
RCS ARCA 7050	Rain canopy set for size 7050
MPP ARCA 7050	Mounting plate perforated (630x430x2 mm - 26x11 mm)
DSP ARCA LM	Door stopper ARCA, left, midsize 5070-8060
DRS ARCA 705030	DIN rail frame set (685 x 485 x 35)
MPS ARCA 7050	Mounting plate (630x430x2 mm) (630 x 430 x 2)
MPMP ARCA 7050	Mounting plate multiperforated (630x430x2 mm - ø3.6 mm)
PMK ARCA 50	PoleMounting kit, for pole ø100-300mm (485 x 385 x 35)

#### **Ratings :**

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C

#### **Certificates :**

Certificate FI 40467