

# EKHA 130 T



Sample image

**Order symbol :** EKHA 130 T

**Product nr :** 2538101

**Description :** Enclosure, PC


**Remarks :** Transparent cover

**EAN :** 6418074013712

**El. number :**

- Finland : 3425450
- Denmark : 8212050772
- Sweden : 2538101

**Including :** Flanged Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

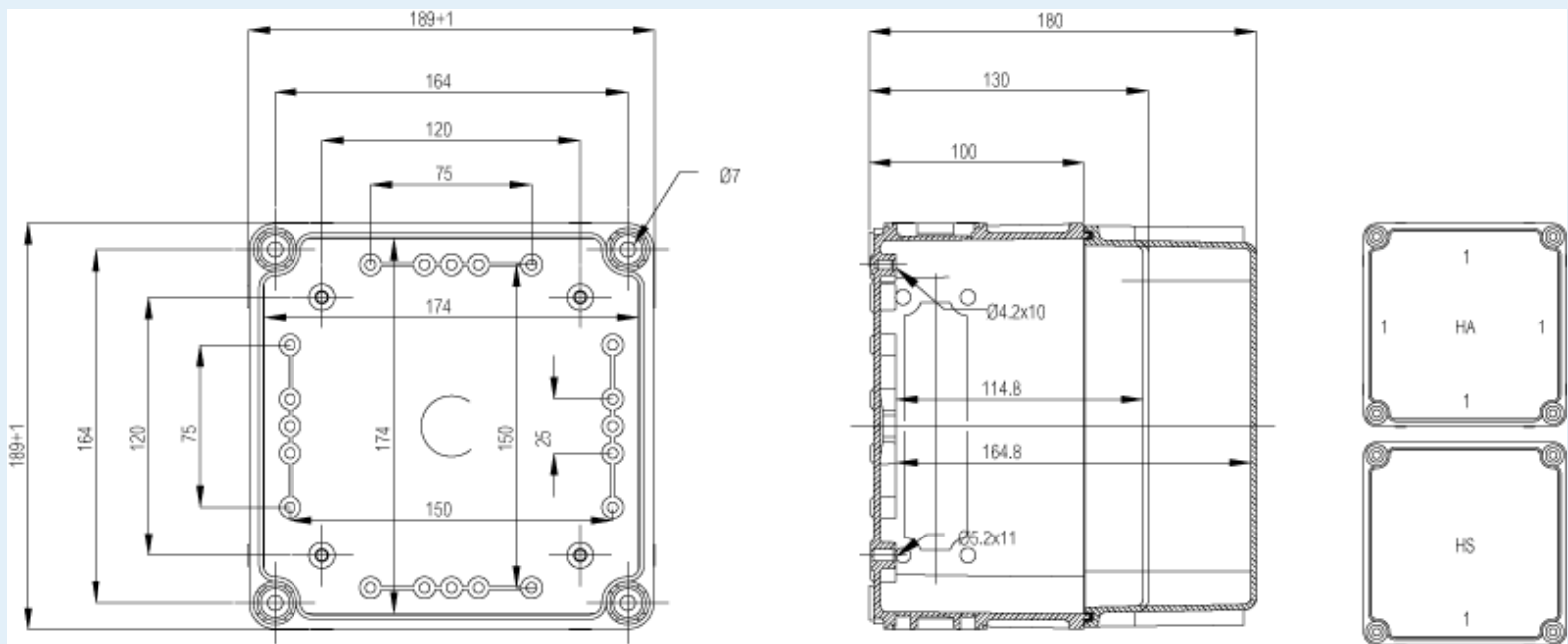

Dimensions :	Height	Width	Depth
mm :	190	190	130

## Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

## Accessories :

EKHVT	Mounting plate, for enclosures: (148 x 148 x 1)
EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)
MPI EKH 1919	Multiperforated plastic mounting plate (167 x 167 x 4)

## Ratings :

Ingress protection (EN 60529):	IP66; IP67;
--------------------------------	-------------

**Temperatures :**

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

SGSFIMKO\_EK