

# EKUN 180 T



Sample image

**Order symbol :** EKUN 180 T

**Product nr :** 2538185

**Description :** Enclosure, PC




**Remarks :** Transparent cover

**EAN :** 6418074013965

**El. number :**

- Finland : 3425488
- Denmark : 8212051111
- Sweden : 2538185

**Including :** Flanged Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

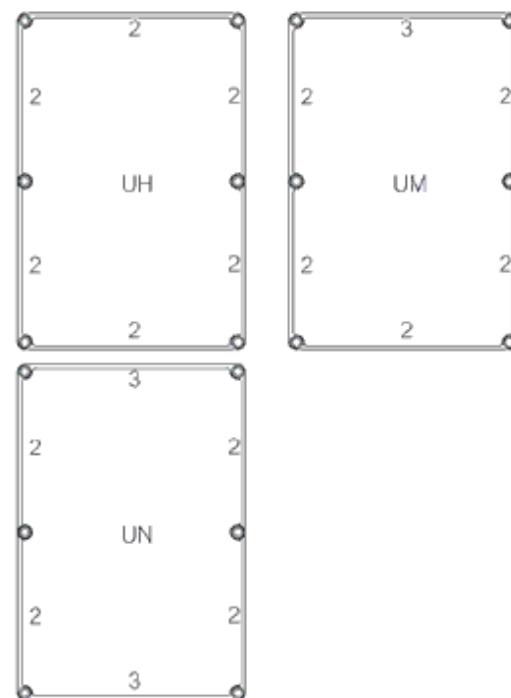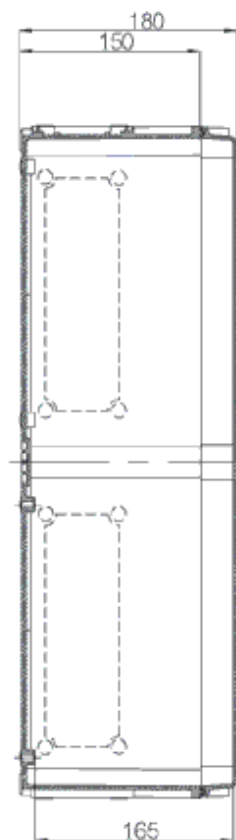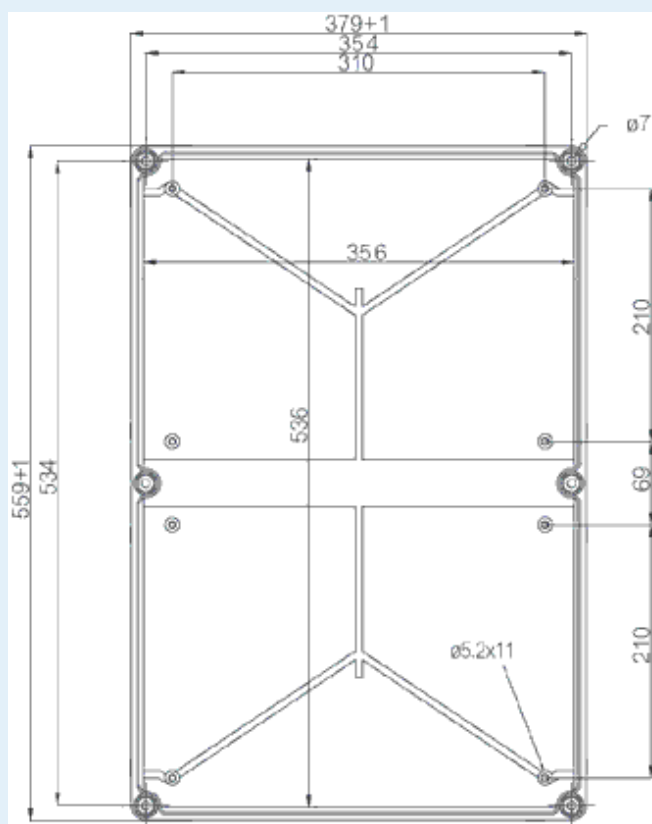

**Dimensions :**

mm :

**Height**

560

**Width**

380

**Depth**

180

**Accessories :**

EKUVT Mounting plate, for enclosures:  
(518 x 338 x 1)

EKV 32 DIN-35 Mounting rail, for enclosures:  
(335 x 35 x 1)

**Materials :**

|                   |                   |
|-------------------|-------------------|
| Material :        | Polycarbonate     |
| Base colour :     | RAL_7035          |
| Cover colour :    | Clear transparent |
| Gasket material : | Polyurethane      |

**Temperatures :**

|                               |             |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

|       |                                                      |
|-------|------------------------------------------------------|
| EKUZR | Extension frame, for enclosures:<br>(560 x 380 x 50) |
|-------|------------------------------------------------------|

**Ratings :**

|                                         |                   |
|-----------------------------------------|-------------------|
| Ingress protection (EN 60529):          | IP66; IP67;       |
| Impact Resistance (EN 62262):           | IK08;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | UL 746C           |
| Flammability Rating :                   | UL 94 V0          |
| Glow Wire Test (IEC 695-2-1) °C :       | 960C              |

**Certificates :**

SGSFIMKO\_EK