

# PCQ3 203612



Sample image

**Order symbol :** PCQ3 203612

**Product nr :** 7035791

**Description :** Enclosure, PC


**Remarks :** Grey cover (quick-locking)

**EAN :** 6418074099372

**El. number :**

- Finland : 3424266
- Denmark : 8212051975

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

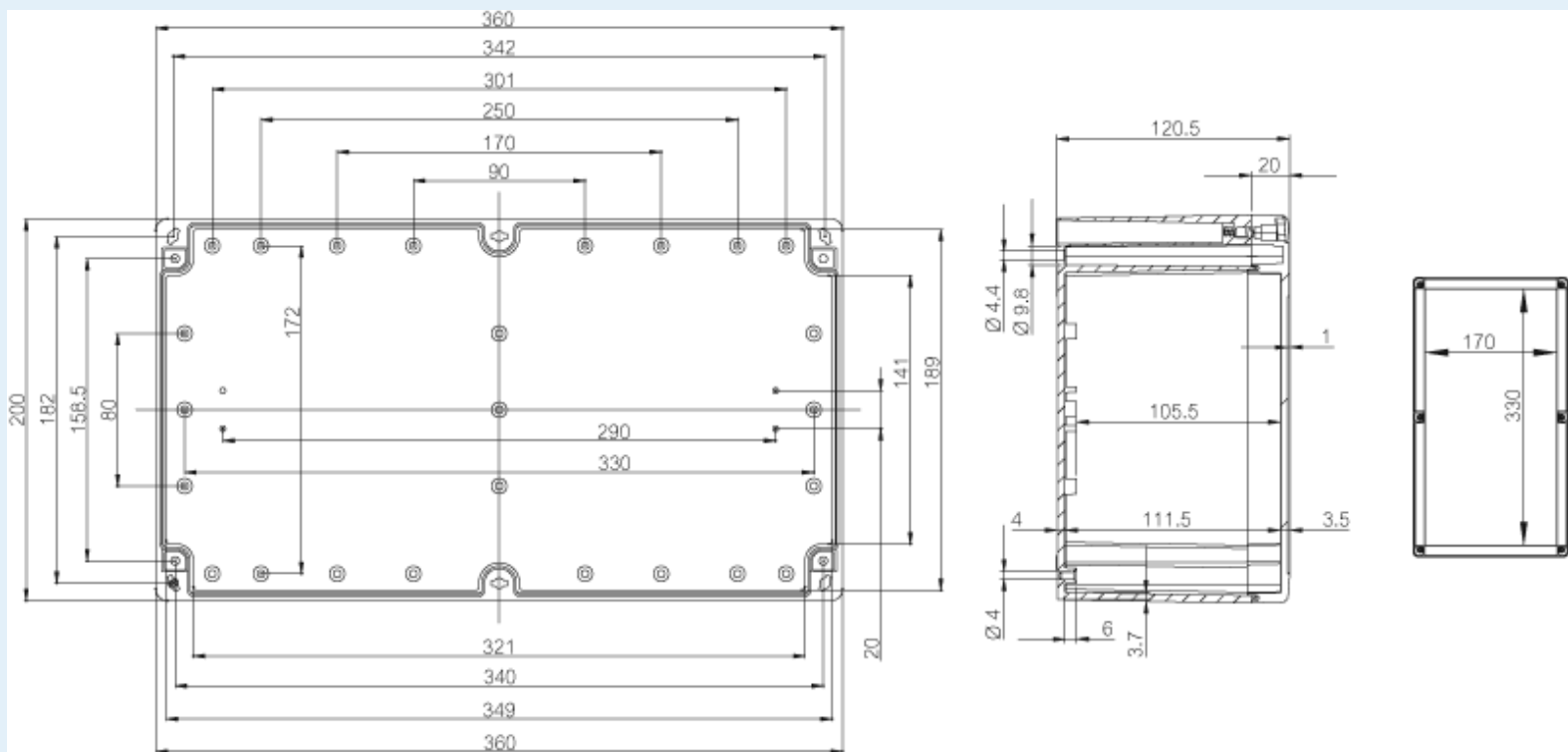

Dimensions :	Height	Width	Depth
mm :	200	360	120
inch :	7.87	14.17	4.72

**Materials :**

Material : Polycarbonate

**Accessories :**

- TF 28037 Wall fastening lug (4 pcs), for enclosures:
- TM 2036 Mounting plate, for enclosures: (318 x 186 x 1)
- TH A Grey plastic hinges (2 pcs)
- TRH 2036 DIN-35 Mounting rail, for enclosures: (35 x 340 x 1)

Base colour :	RAL_7035
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

**Temperatures :**

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

**Ratings :**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

SGSFimko\_EURONORD