

PCTQ3 122410



Sample image

Order symbol : PCTQ3 122410

Product nr : 7025780

Description : Enclosure, PC


Remarks : Smoked transparent cover (quick-locking)

EAN : 6418074099082

El. number :

- Finland : 3424190
- Denmark : 8212051988

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

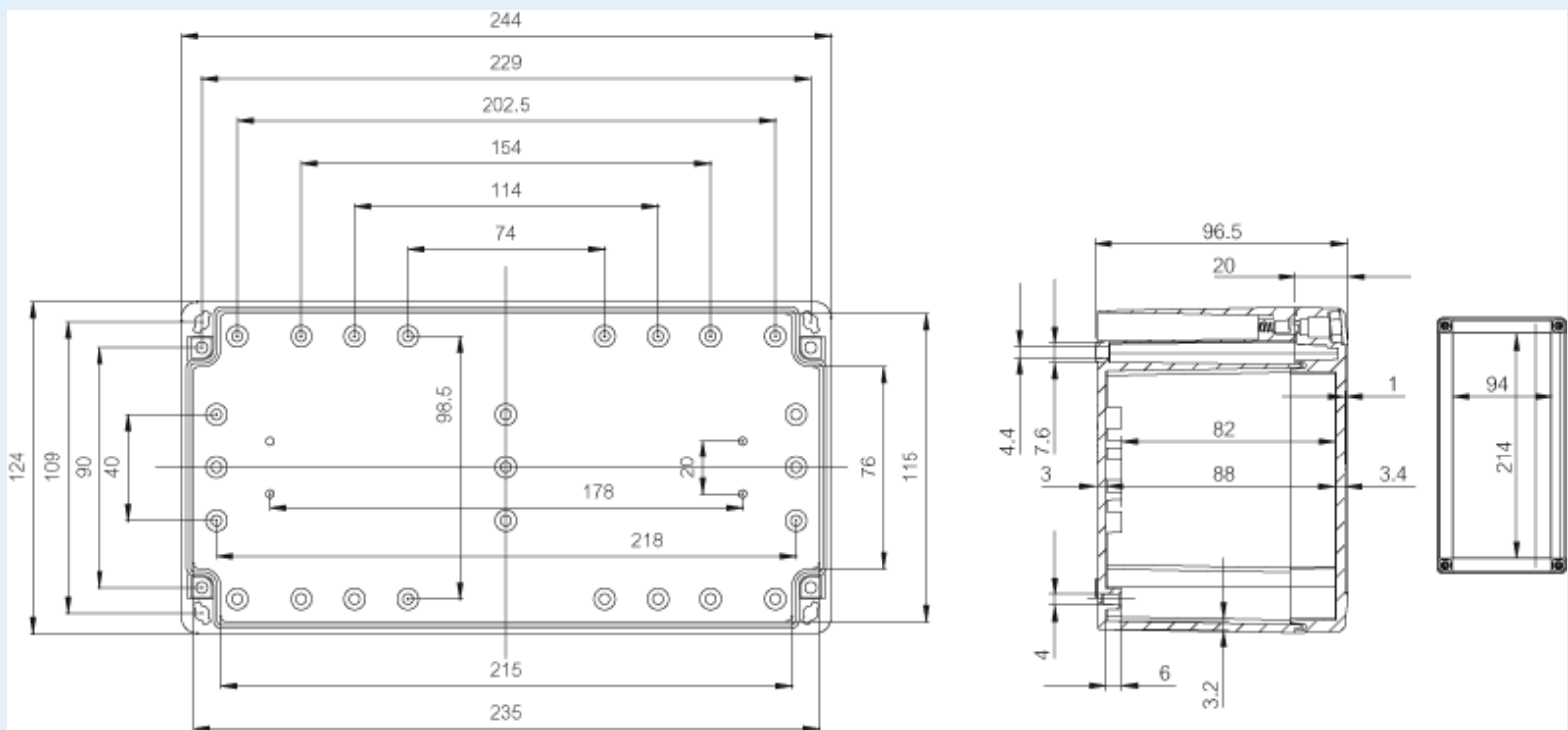

Dimensions :	Height	Width	Depth
mm :	120	240	100
inch :	4.72	9.45	3.94

Materials :

Material : Polycarbonate

Accessories :

TRH 1212	DIN-35 Mounting rail, for enclosures: (110 x 35 x 1)
TRH 24	DIN-35 Mounting rail, for enclosures: (226 x 35 x 1)
TRM 0812	DIN-15 Mounting rail, for enclosures: (106 x 15 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:

Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

MIN 20	DIN-15 Mounting rail, for enclosures: (225 x 15 x 1)
TH A	Grey plastic hinges (2 pcs)
TM 1224	Mounting plate, for enclosures:

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

SGSFimko_EURONORD