

PCTQ3 153410



Sample image

Order symbol : PCTQ3 153410

Product nr : 7025700

Description : Enclosure, PC


Remarks : Smoked transparent cover (quick-locking)

EAN : 6418074099143

El. number :

- Finland : 3424199
- Denmark : 8212051991

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

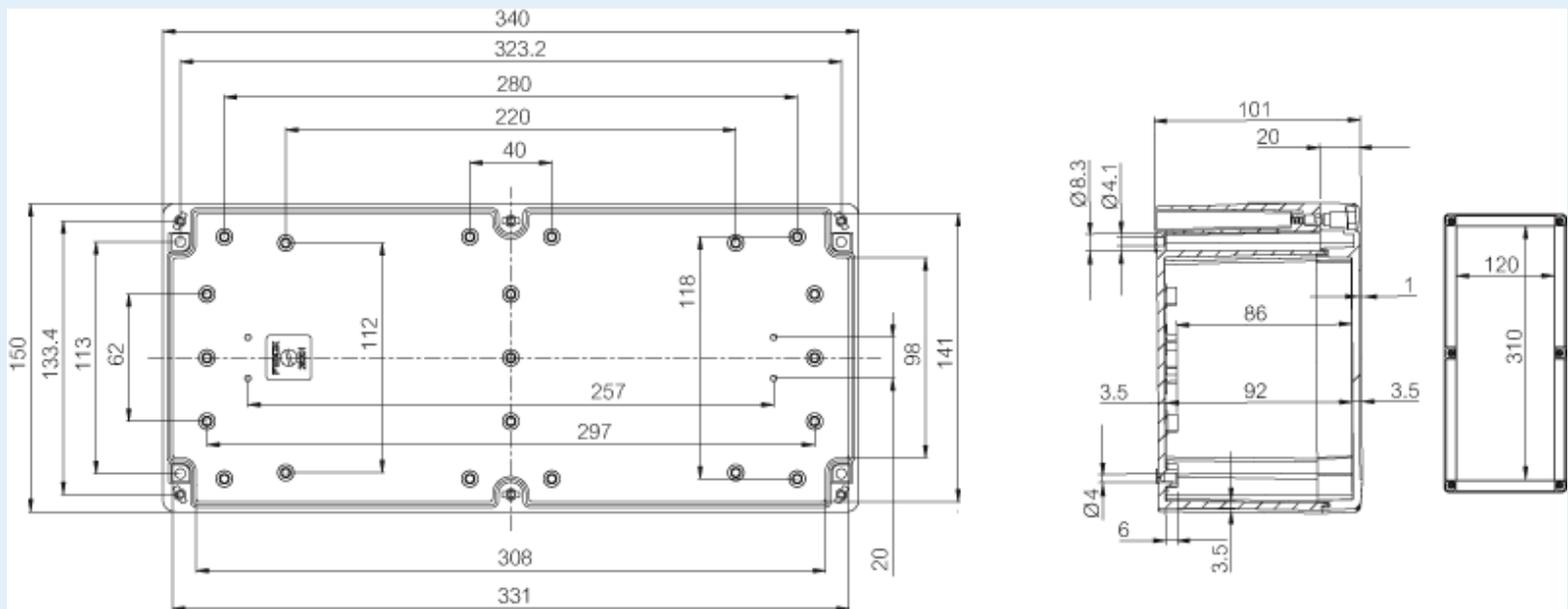

Dimensions :

	Height	Width	Depth
mm :	150	340	100
inch :	5.91	13.39	3.94

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

Accessories :

TRH 34	DIN-35 Mounting rail, for enclosures: (307 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
TRH 15	DIN-35 Mounting rail, for enclosures: (122 x 35 x 1)
TM 1534	Mounting plate, for enclosures: (303 x 136 x 1)
TH A	Grey plastic hinges (2 pcs)

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 V0
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

SGSFimko_EURONORD