

PCTQ3 162409



Sample image

Order symbol : PCTQ3 162409

Product nr : 7025810

Description : Enclosure, PC


Remarks : Smoked transparent cover (quick-locking)

EAN : 6418074099266

El. number :

- Finland : 3424241
- Denmark : 8212052000

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

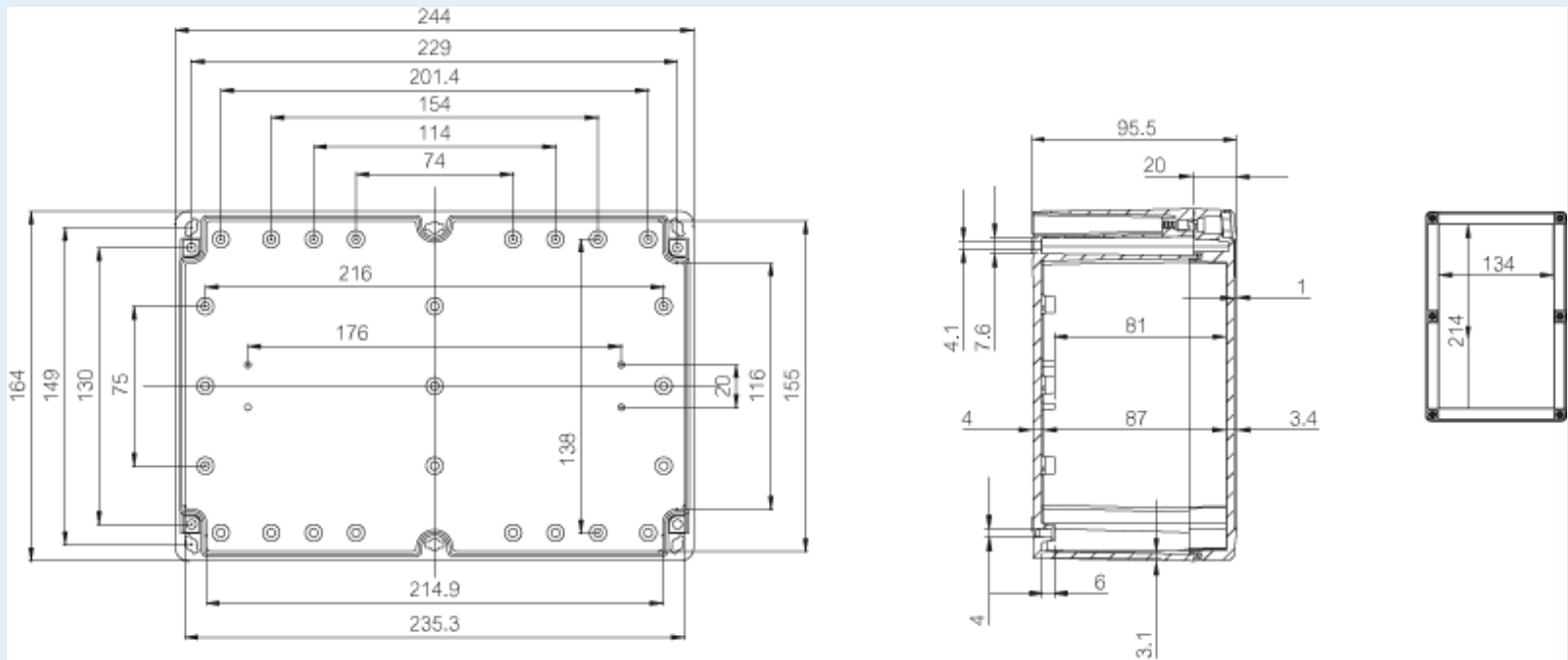

Dimensions :	Height	Width	Depth
mm :	160	240	90
inch :	6.3	9.45	3.54

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent

Accessories :

TRH 24	DIN-35 Mounting rail, for enclosures: (226 x 35 x 1)
TF 28037	Wall fastening lug (4 pcs), for enclosures:
MIN 20	DIN-15 Mounting rail, for enclosures: (225 x 15 x 1)
TM 1624	Mounting plate, for enclosures: (212 x 151 x 1)
TH A	Grey plastic hinges (2 pcs)

Gasket material : Polyurethane

Temperatures :

Temperature °C (continuous) : -40 ... 80

Temperature °F (continuous) : -40 ... 175

Ratings :

Ingress protection (EN 60529): IP66; IP67;

Impact Resistance (EN 62262): IK07; IK08;

electrical_insulation : Totally insulated

Halogen free (DIN/VDE 0472, Part 815) : Yes

UV resistance : UL 746C

Flammability Rating : UL 94 V0

Glow Wire Test (IEC 695-2-1) °C : 960C

Certificates :

SGSFimko_EURONORD