

# PCTQ3 163610



Sample image

**Order symbol :** PCTQ3 163610

**Product nr :** 7025750

**Description :** Enclosure, PC


**Remarks :** Smoked transparent cover (quick-locking)

**EAN :** 6418074099327

**El. number :**

- Finland : 3524261
- Denmark : 8212052013

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

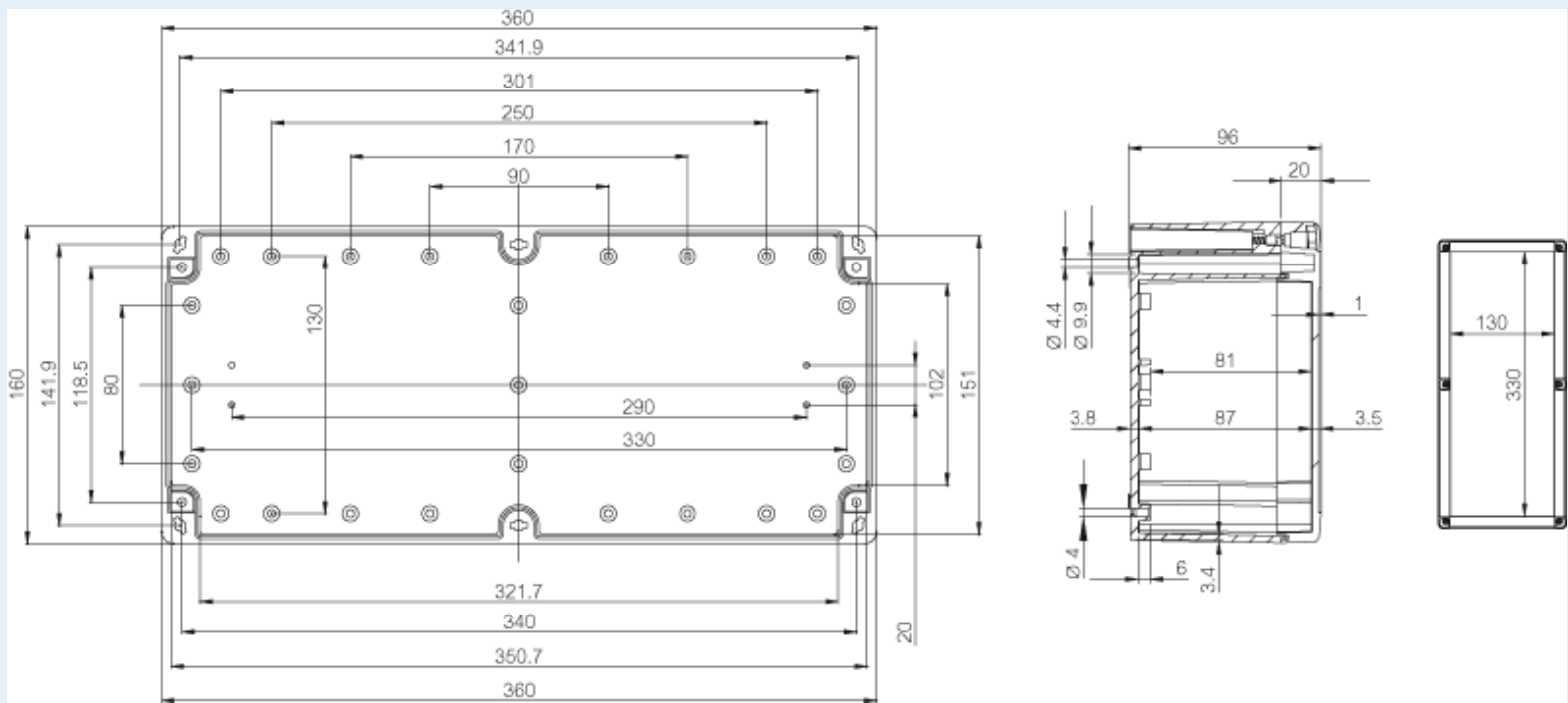

Dimensions :	Height	Width	Depth
mm :	160	360	100
inch :	6.3	14.17	3.94

**Materials :**

Material :	Polycarbonate
Base colour :	RAL_7035

**Accessories :**

TF 28037	Wall fastening lug (4 pcs), for enclosures:
ARM 0615	DIN-15 Mounting rail, for enclosures: (140 x 15 x 1)
TM 1636	Mounting plate, for enclosures: (318 x 146 x 1)
DH-3	DIN-35 Mounting rail, for enclosures: (140 x 35 x 1)
TH A	Grey plastic hinges (2 pcs)

Cover colour : Clear transparent  
Gasket material : Polyurethane

TRH 2036 DIN-35 Mounting rail, for enclosures:  
(35 x 340 x 1)

**Temperatures :**

Temperature °C (continuous) : -40 ... 80  
Temperature °F (continuous) : -40 ... 175

**Ratings :**

Ingress protection (EN 60529): IP66; IP67;  
Impact Resistance (EN 62262): IK07; IK08;  
electrical\_insulation : Totally insulated  
Halogen free (DIN/VDE 0472, Part 815) : Yes  
UV resistance : UL 746C  
Flammability Rating : UL 94 V0  
Glow Wire Test (IEC 695-2-1) °C : 960C

**Certificates :**

SGSFimko\_EURONORD